


## Cabinet Accessories – Socket strips

### IEC socket strip, C13

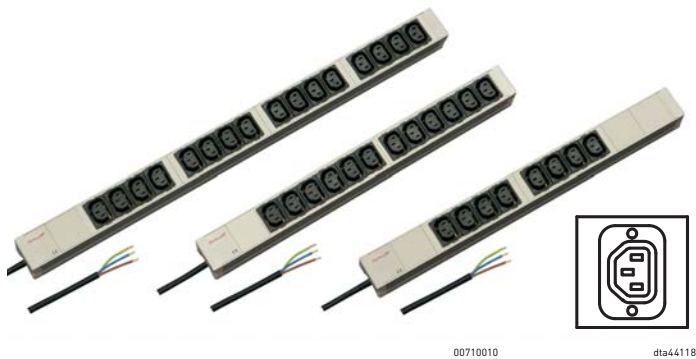

- Socket strips with IEC 60320-C13 sockets
- Mounting height 1 U
- Connecting cable 2 m, open end with ferrules
- Socket strips can be rotated through all four directions (in 90° increments) during installation
- Horizontal and vertical mounting
- 230 V, 10 A
- In accordance with IEC 60320



#### Delivery comprises (assembled)

Item	Qty	Description
1	1	Al extrusion, 1 U, anodised, to accommodate the sockets and function elements
2		IEC 60320-C13 sockets (PA, RAL 7035), quantity see Order information
3	2	End piece, PA, RAL 7035
4	1	Connecting cable, 2 m, black, open end with ferrules, H05VV-F 3G 1.5 mm <sup>2</sup>
5	2	Mounting bracket, PA, RAL 7035, (on 19" versions only)

#### Order Information


Sockets	Length Inch	Length mm	Depth mm	Part no.
8	19"	438.5	44	60110-290
12	19"	438.5	44	60110-291
16	–	608.5	44	60110-292

<b>Delivery: fitted in cabinet or on frame</b>	<b>Part no./05</b>
<b>Delivery: supplied loose with cabinet or frame</b>	<b>Part no./35</b>

Accessories		Part no.
<b>Locking tab for IEC 60320-C13 connector</b>	PU 12 pieces	60110-362
<b>Item 6 Mounting bracket for socket strips</b>	for vertical mounting, St, 2 mm, PU 2 pieces	20110-068
<b>Mounting plate for mounting of two socket strips side by side</b>	for vertical mounting, St, 2 mm, height 70 mm, depth 135 mm, PU 2 pieces	23130-010
<b>Mains cable, IEC</b>	for locking tab IEC 60320-C14 plug, IEC 60320 C13 socket, 0.5 m, 1 piece	60110-360
<b>Mains cable, IEC</b>	for locking tab IEC 60320-C14 plug, IEC 60320 C13 socket, 1 m, 1 piece	60110-361

#### Note

- Please order bracket for vertical mounting separately
- IEC socket strips, telemonitored and remote-controlled see page 3.75
- IEC socket strips with universal connections (Wieland® connectors) see page 3.67
- Individual online configuration [www.schroff.biz/conf](http://www.schroff.biz/conf)

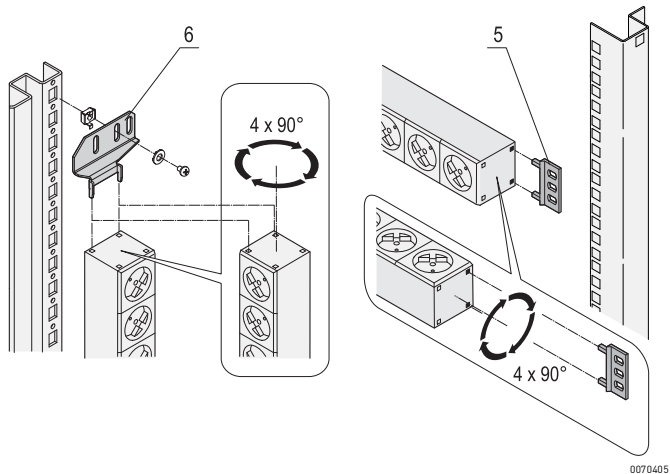

Item 6: bracket for vertical mounting



Strain relief provided by locking tabs



ServicePLUS see page 3.71