


# MINI PIR MOTION DETECTOR - FLUSH MOUNT - 230 VAC

 [vulleman.eu/products/view](https://vulleman.eu/products/view)

EMS106

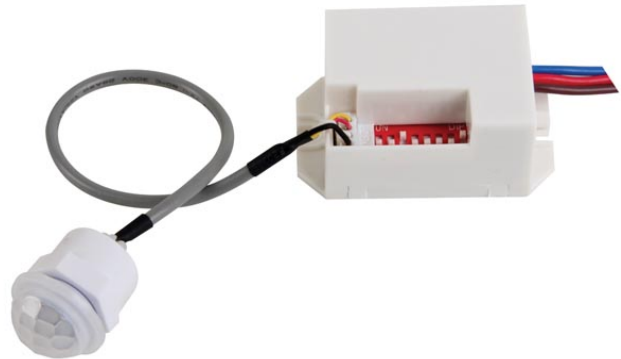

## Features

- with automatic day/night detection
- adjustable: activation period, light sensitivity (TIME - LUX)
- flush mount

## Specifications

### Physical Properties

Wire Length             $\pm 18$  cm

Height Pir Sensor    10 mm

### Electrical Data

Maximum Rated Current Fluorescent    1.25 A

Maximum Rated Current Tungsten        3.3 A

Maximum Rated Load Fluorescent        200 W

Maximum Rated Load Tungsten            800 W

### Technical Data

## Technical Data

Diameter PIR sensor 22 mm

---

Mounting Type Flush Mount

---

PIR Sensor Settings Adjustable Light Sensitivity (LUX), Adjustable Time Delay (TIME)

## Set-up Options

Detection angle 100 °

---

Light Sensitivity 3-2000 lx

## Environmental Data

IP Rating IP20

---

Operating Temperature -10-40 °C

---

Usage Location indoor only

---

Maximum Operating Humidity 93 %

## Operational Properties

Instruction Manual Languages Dutch, English, French, German, Polish, Portuguese, Spanish

---

Switch Type Relay

---

Automatic Day/Night Detection

---

Detection Range 8 m

---

Time Delay Switch 1 min, 30 s, 3 min, 5 min, 5 s, 8 min

---

Mounting Hole Diameter ± 14 mm

## Power Supply

Input Voltage Rating VAC 220-240 V

---

Input Frequency Rating 50 Hz

## Included

LED Indicator

### **Product Basic Info**

Colour	White
--------	-------

---

Height	42 mm
--------	-------

---

Depth	35 mm
-------	-------

---

Width	22 mm
-------	-------

---

Weight	41 g
--------	------

---

Material	ABS
----------	-----