


MINI PIR MOTION DETECTOR - FLUSH MOUNT - 12 VDC

 velleman.eu/products/view

EMS114

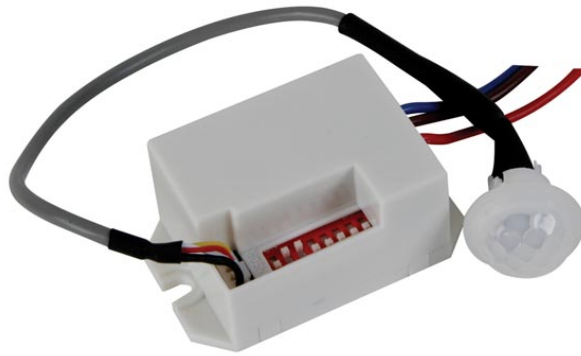

Features

- with automatic day/night detection
- adjustable: activation period, light sensitivity (TIME - LUX)
- flush mount

Specifications

Physical Properties

Wire Length ± 18 cm

Height Pir Sensor 10 mm

Technical Data

Diameter PIR sensor 22 mm

Mounting Type Flush Mount

PIR Sensor Settings Adjustable Light Sensitivity (LUX), Adjustable Time Delay (TIME)

Set-up Options

Set-up Options

Detection angle 100 °

Light Sensitivity 3-2000 lx

Environmental Data

IP Rating IP20

Operating Temperature -10-40 °C

Usage Location indoor only

Maximum Operating Humidity 93 %

Operational Properties

Instruction Manual Languages Dutch, English, French, German, Polish, Portuguese, Spanish

Switch Type Relay

Automatic Day/Night Detection

Detection Range 8 m

Time Delay Switch 1 min, 30 s, 3 min, 5 min, 5 s, 8 min

Mounting Hole Diameter ± 12 mm

Power Supply

Input Current Rating 2.6 A

Input Voltage Rating Vdc 11-13 V

Included

LED Indicator

Product Basic Info

Colour White

Height 40 mm

Depth 10 mm

Width 22 mm

Product Basic Info

Weight 41 g

Material ABS