

Zack marker strip - ZB 10/BU CUS - 0824934

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Zack marker strip, can be ordered: Strip, blue, labeled according to customer specifications, mounting type: snap into tall marker groove, for terminal block width: 10.2 mm, lettering field size: 10.5 x 10.15 mm

The figure shows versions ZB 10 - UNPRINTED, -LGS:CONSEC.NOS, -QR:CONSEC.NOS and -SO/CMS



Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 358873
GTIN	4046356358873
Custom tariff number	49119900
Country of origin	Germany

Technical data

Dimensions

Width (a)	10 mm
-----------	-------

Ambient conditions

Ambient temperature (operation)	-40 °C ... 100 °C
---------------------------------	-------------------

General

Color	blue
Type	high
Components	free from silicone and halogen
Flammability rating according to UL 94	V2
Material	PA

Zack marker strip - ZB 10/BU CUS - 0824934

Technical data

General


Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
Number of individual labels	10
Number of individual labels per row	10
Number of marker strips	10
Marking mounting type	snap into tall marker groove

Standards and Regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
Flammability rating according to UL 94	V2

Drawings

Schematic diagram

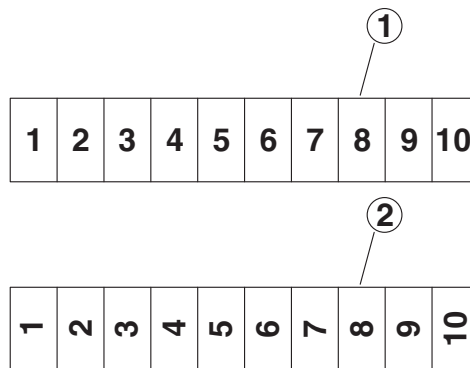

- ① Horizontal
- ② Vertical

Classifications

eCl@ss

eCl@ss 4.0	24190219
eCl@ss 4.1	24190219
eCl@ss 5.0	27141137
eCl@ss 5.1	27141137
eCl@ss 6.0	27141137
eCl@ss 7.0	27141137
eCl@ss 8.0	27141137
eCl@ss 9.0	27141137

Zack marker strip - ZB 10/BU CUS - 0824934

Classifications

ETIM

ETIM 3.0	EC000761
ETIM 4.0	EC000761
ETIM 5.0	EC000761
ETIM 6.0	EC000761

UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39131505