


ball valve

QH-1/4

Part number: 9541

FESTO

Manuel brass ball valve with ISO 228 thread.
This type is suitable for vacuum.

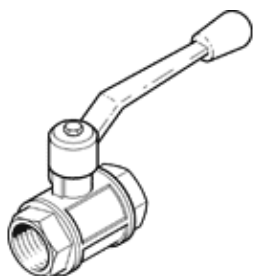

Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	G1/4
Type of actuation	manual
Mounting type	Line installation
Standard nominal flow rate	3,400 l/min
Nominal size	10 mm
Ambient temperature	-20 ... 180 °C
Material housing	Brass
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water
Sealing principle	soft
Design structure	Ball valve
Nominal pressure of process valve	30
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)