


Pressure pipe flange, 1/2 inch

Part no. R1/2"-MCS
Catalog No. 031617
Eaton Catalog No. MCSX-R1-2

Delivery program

Product range		Accessories
Basic function		Pressure pipe flange
		Article no. when ordered separately Other than standard version
For use with		MCS with R 1/2"

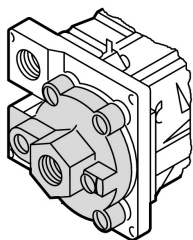

Notes

Design verification as per IEC/EN 61439

Technical data for design verification		
Operating ambient temperature min.	°C	-25
Operating ambient temperature max.	°C	70

Technical data ETIM 7.0

Low-voltage industrial components (EG000017) / Accessories for low-voltage switch technology (EC002498)		
Electric engineering, automation, process control engineering / Low-voltage switch technology / Component for low-voltage switching technology / Component for low-voltage switch technology (accessories) (ecl@ss10.0.1-27-37-13-92 [AKN570013])		
Type of accessory		Connection technique

Approvals

Product Standards		CSA-CC22.2 No. 14
CSA File No.		12528
CSA Class No.		3211-06
North America Certification		CSA certified

Additional product information (links)

IL05212001Z (AWA1320-0132) Pressure switch	
IL05212001Z (AWA1320-0132) Pressure switch	ftp://ftp.moeller.net/DOCUMENTATION/AWA_INSTRUCTIONS/IL05212001Z2018_05.pdf