


## Product information

Installation Cable Cat. 5e, U/UTP, 4P, 200 MHz, PVC,  
Eca, 500 m

R35044  
101771901  
500 m

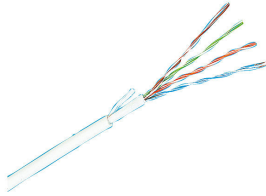

Cat. 5e, U/UTP cable. 100 Ohm impedance. Data transmission frequencies of up to 200 MHz.

020.0980 / similar product

### Technical Data

DESCRIPTION [UNIT]	VALUE/VALUE RANGE
Standard	ISO/IEC 11801-1 Ed 1.0 2017-11 IEC 61156-5 2 <sup>nd</sup> ed. EN 50173-1 EN 50288-3-1 TIA 568-C.2 Fire classification: IEC 60332-1 CPR fire class: EN50575
Protection class IP	IP 20
PoE	Yes
Cable type	installation cable
Category	Cat. 5e
Shielding	U/UTP
Jacket material	PVC
Fire rating	Eca
Cable jacket characteristics	Flame-retardant
Cable protection	No protection
Cable overall diameter	Ø 5.1 mm
Wire diameter	AWG 24
Cable design	normal
Number of wires	8
Stranding	4 pairs
Wire type	Wire
Max. test frequency	200 MHz

### Mechanical Data

<b>DESCRIPTION [UNIT]</b>	<b>VALUE/VALUE RANGE</b>
Cable length	500 m
Color Code RAL	7035 Light gray