


18U 19" Wall Mount Network Rack - Adjustable Depth 12-20" 2 Post Open Frame Server Room Rack for AV/Data/ IT Communication/Computer Equipment/Switch w/Cage Nuts & Screws

Product ID: RACK-18U-20-WALL-OA

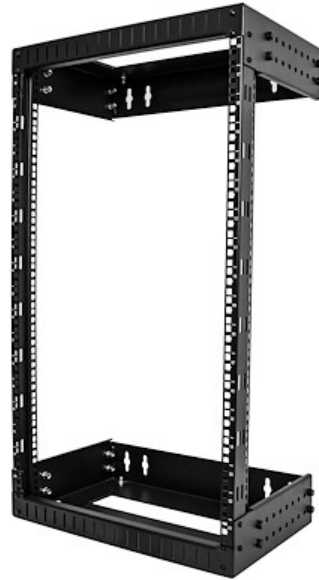

The RACK-18U-20-WALL-OA 18U Open Frame Wall Mount Equipment Rack with Adjustable Depth is a high-quality, sturdy relay rack solution that is easy to assemble and install into any environment.

The open rack features an adjustable depth ranging from 12-20 inches to accommodate larger data, network, and telecommunications devices. With a maximum depth of 20 inches, this rack allows for mounting of shelves and other accessories with enough clearance at the back for cable management. The open-frame design help to keep your equipment cool and easily accessible from different angles. The wall mounting holes are positioned 12 and 16 inches apart (center to center) providing a convenient and effecting anchoring, making it suitable for mounting on virtually any wall surface or construction framework.

This 18U rack includes M6 square cage nuts and M6 screws to save you the hassle of sourcing separate mounting hardware for your equipment. This rack can be mounted to the wall in a server room, data closet, or office expanding your valuable floor space.

The RACK-18U-20-WALL-OA is backed for 5-years by StarTech.com, including free lifetime 24/5 multi-lingual technical assistance.

Certifications, Reports and Compatibility

Applications

Features

- **ADJUSTABLE DEPTH:** This 2-post 18U 19 inch open frame rack is EIA/ECA-310 compliant, and with an adjustable

mounting depth ranging from 12 - 20 inches, is ideal for network switches, servers, patch panels, and PDUs

- **HEAVY DUTY:** This durable rack has a 2.0mm thick vertical rail SPCC cold-rolled steel and a weight capacity of up to 200 lbs (90 kg). Its design supports unobstructed airflow to help keep your equipment cool and easy to install with access to all sides
- **ACCESSORIES INCLUDED:** The wall mount equipment rack includes a complete set of M6 square cage nuts and M6 screws to securely mount all of your equipment in the rack and also features comprehensive assembly instructions
- **CERTIFIED PACKAGING:** The rack ships flat packed to ensure complete and undamaged delivery and is ISTA-6 certified
- **STARTECH.COM ADVANTAGE:** IT professionals choice for over 30 years; This 2-post adjustable wall-mounted rack is backed by a 5-year warranty, including free lifetime 24/5 North America based multi-lingual tech support

Hardware

Warranty	5 Years
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Open Frame
U Height	18U
Special Features	Easy Assembly
Mounting Rail Profile	G-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

Performance

Weight Capacity	198.9 lb [90 kg]
-----------------	------------------

Physical Characteristics

Color	Black
Construction Material	Steel
Product Length	20.0 in [50.8 cm]
Product Width	19.8 in [50.4 cm]
Product Height	35.7 in [90.6 cm]



Weight of Product 34.9 lb [15.8 kg]

Maximum Mounting Depth 20.0 in [50.8 cm]

Packaging Information

Package Length 3.8 ft [1.2 m]

Package Width 16.5 in [42.0 cm]

Package Height 6.3 in [16.0 cm]

Shipping (Package) Weight 43.5 lb [19.7 kg]

What's in the Box

Included in Package

- 2 - Front Horizontal Brackets
- 2 - Rear Horizontal Brackets
- 2 - Vertical Brackets
- 72 - M6 Cage Nuts
- 72 - M6 Cage Screws
- 72 - Plastic Washers
- 16 - M5x12mm Assembly Screws
- 24 - M8x16mm Bolts
- 24 - #8 Flat Washers
- 1 - Quick-Start Guide

****Product appearance and specifications are subject to change without notice.***

