

DIP switch

8P

FEATURES:


Electrical life 2,000 operations

Switching rating 25mA, 24VDC

Soldering temperature 260°C for 5±1sec


SPECIFICATION:

Poles	8
Pitch	2.54 mm
Actuation	Piano
Contact resistance	50 mΩ
Contact material	Phosphor bronze
Test voltage	500 VAC
Temperature range	-20...+70 °C

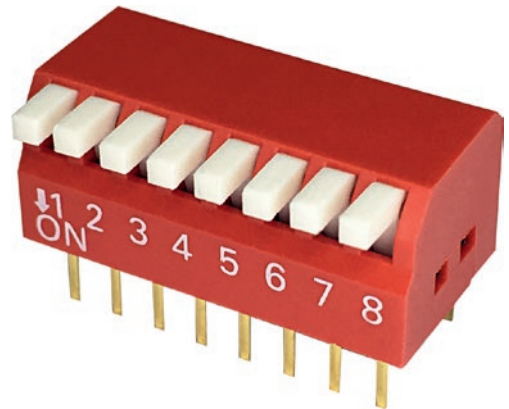

Art. Nr.

RND 210-00170

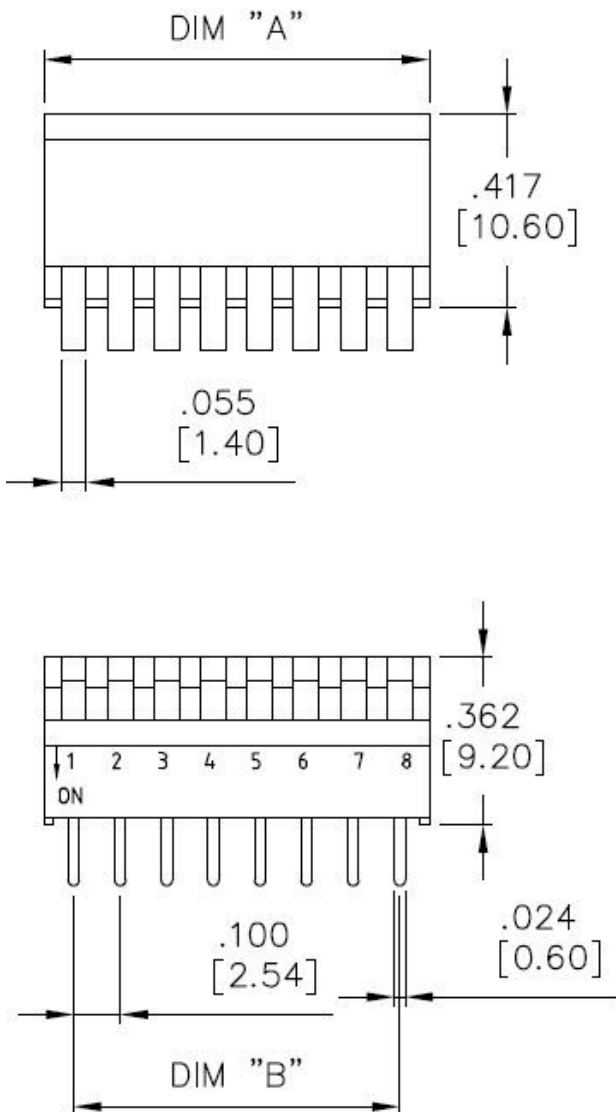

Construction

