

PCB coding switch


HEX 3+2



FEATURES:





SPECIFICATION:

Switching type	HEX
Pins	3+2
Pitch	2.54 mm
Actuation	above
Switching capacity	0.15 A@ 42 VDC
Contact resistance	80 mΩ
Temperature range	-10...+70 °C
Height	6.8 mm
Length	10 mm
Width	10 mm
Actuation force	686.5 N
Protection rating	IP 67

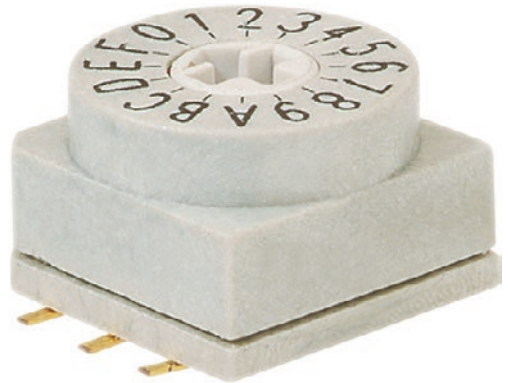

Art. Nr.

RND 210-00244

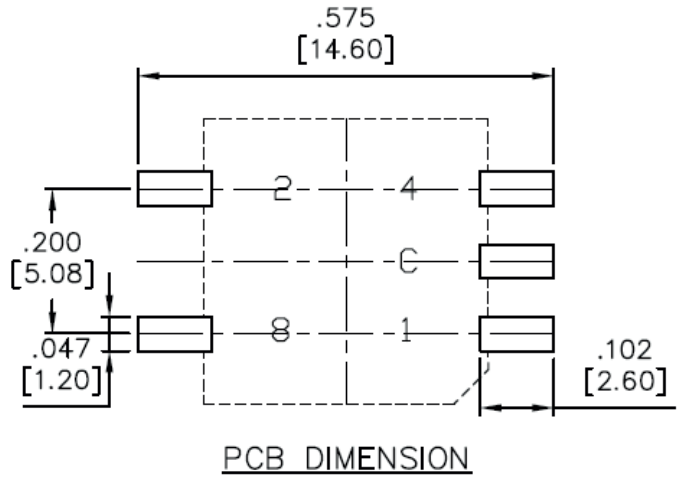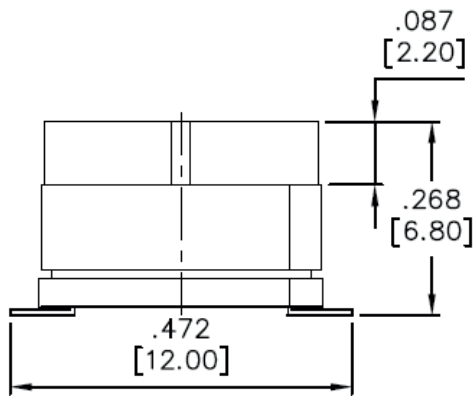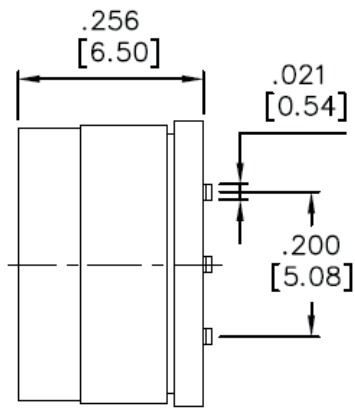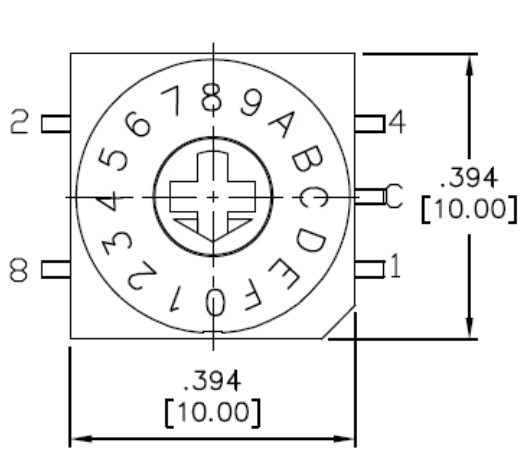

CODE NO:12
10 POSITION

CODE NO:14
16 POSITION

		Real code				
		C	1	2	4	8
10 Position	0	●				
	1	●	●			
	2	●		●		
	3	●	●	●		
	4	●			●	
	5	●	●		●	
	6	●		●	●	
	7	●	●	●	●	
	8	●				●
	9	●	●			
16 Position	A	●		●		●
	B	●	●	●		●
	C	●			●	●
	D	●	●		●	●
	E	●		●	●	●
	F	●	●	●	●	●

