

Miniature Thermocouple Connector Socket

Features


- Easy jab-in connection
- Push in wire & tighten screw
- Contacts are polarised to prevent incorrect termination



Specification

Sensor Type	K
Connector Size	Miniature
Connector Type	Quick Wire Socket
Colour	Yellow
Max. Temperature	220 °C
+Positive Contact	NiCr
-Negative Contact	NiAl
Standards Met	BS EN 50212:1997; RoHS

Drawing

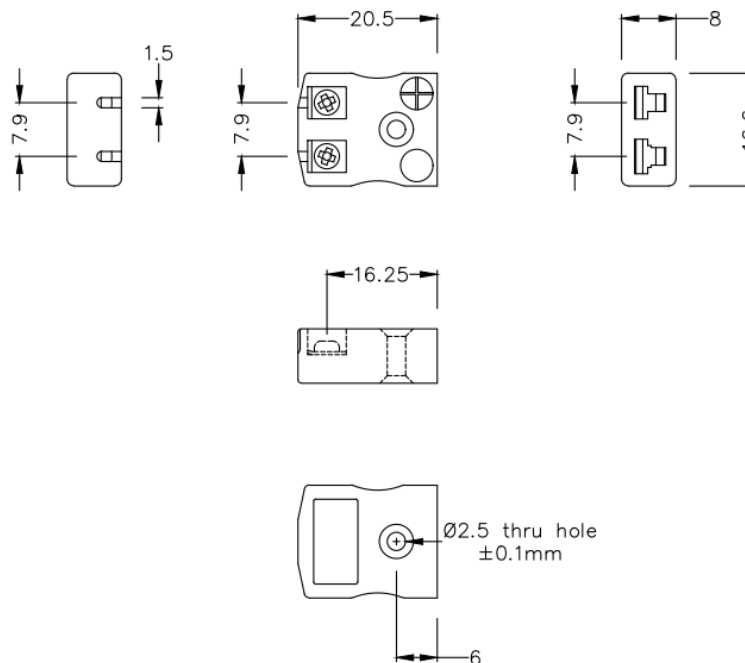

Miniature in-line Socket - Quick Wire

(dimensions in mm)

Art. Nr.
RND 410-00183