

Standard Panel Mount with Stainless Steel Bracket



Features


- Intended for use in more industrial processes but can be used in all applications
- Easy 'jab-in' connection for rapid termination
- Just push wire in and tighten screw



Specification

Sensor Type	J
Connector Size	Standard
Connector Type	Quick Wire Socket with SS Bracket
Colour	Black
Max. Temperature	220°C
+Positive Contact	Fe
-Negative Contact	CuNi
Standards Met	BS EN 50212:1997; RoHS

Drawing

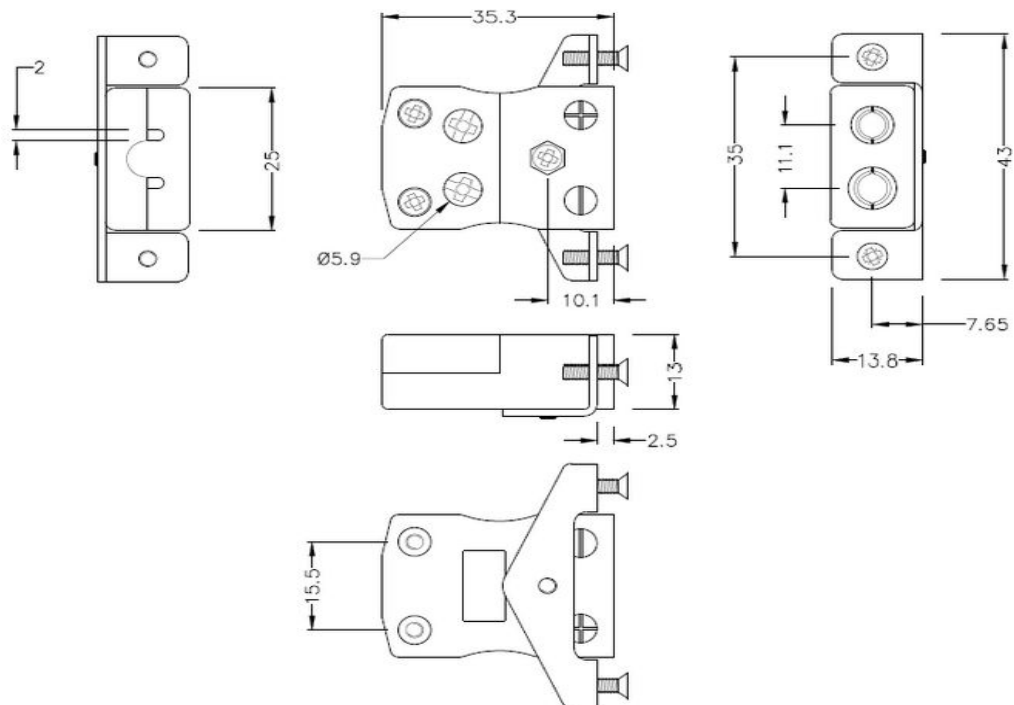

Standard Socket - Quick Wire with stainless steel mounting bracket
(dimensions in mm)

Art. Nr.
RND 410-00213