

Standard Rectangular Fascia Thermocouple Socket



Features


- Polyamide clip for quick, simple fixing to panel
- All fascia mounting sockets are polarised by means of unequally sized pins
- Accepts standard round pin plug connector



Specification

Sensor Type	T
Connector Size	Standard
Connector Type	Fascia Mounting Socket
Colour	Brown
Max. Temperature	120 °C
+Positive Contact	Cu
-Negative Contact	CuNi
Standards Met	BS EN 50212:1997; RoHS

Drawing

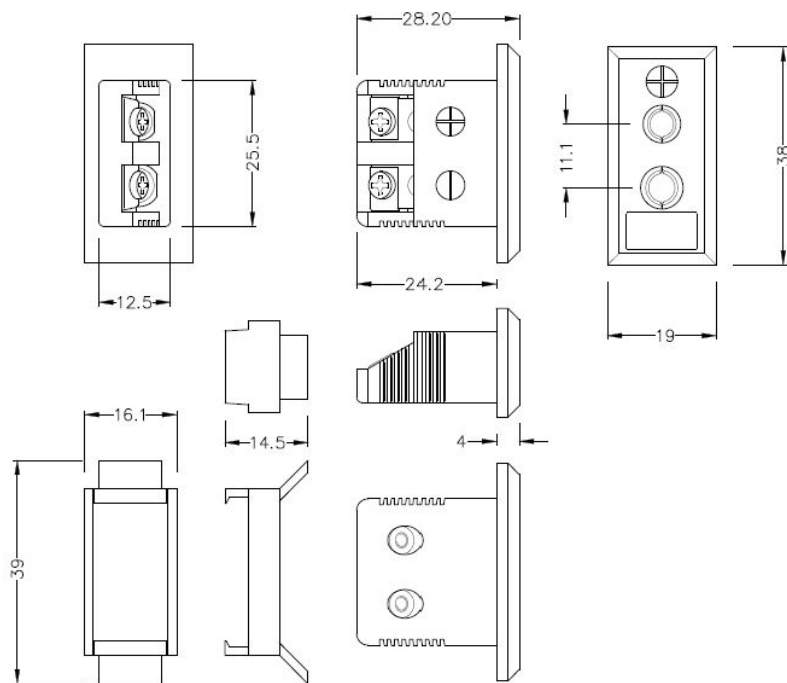

Standard Fascia Socket (with nylon mounting clip)

(dimensions in mm)

Art. Nr.
RND 410-00220