

# 19" Cases

## 19" Wall Mounted Cabinets with Glass Door



### FEATURES:

19" Wall mounted cabinet with glass door  
Compact design with self-supporting frame  
Load capacity max. 100 kg  
Removable sidepanel (front door must be open)  
Complies with EN60529 (IP20) and IEC297-II  
Fully adjustable 19" mounting angles  
Top and bottom frames with pre-punched openings  
Used for Indoor Applications/Facilities




### SPECIFICATION:

Colour grey/RAL 7035  
Protection rating IP 20

### PRODUCT RANGE:

Art. Nr.	Width	Height	Length	Height units
RND 455-00990	600 mm	365 mm	400 mm	6 HE
RND 455-00991	600 mm	543 mm	400 mm	10 HE
RND 455-00992	600 mm	632 mm	400 mm	12 HE
RND 455-00993	600 mm	365 mm	600 mm	6 HE
RND 455-00994	600 mm	543 mm	600 mm	10 HE
RND 455-00995	600 mm	632 mm	600 mm	12 HE

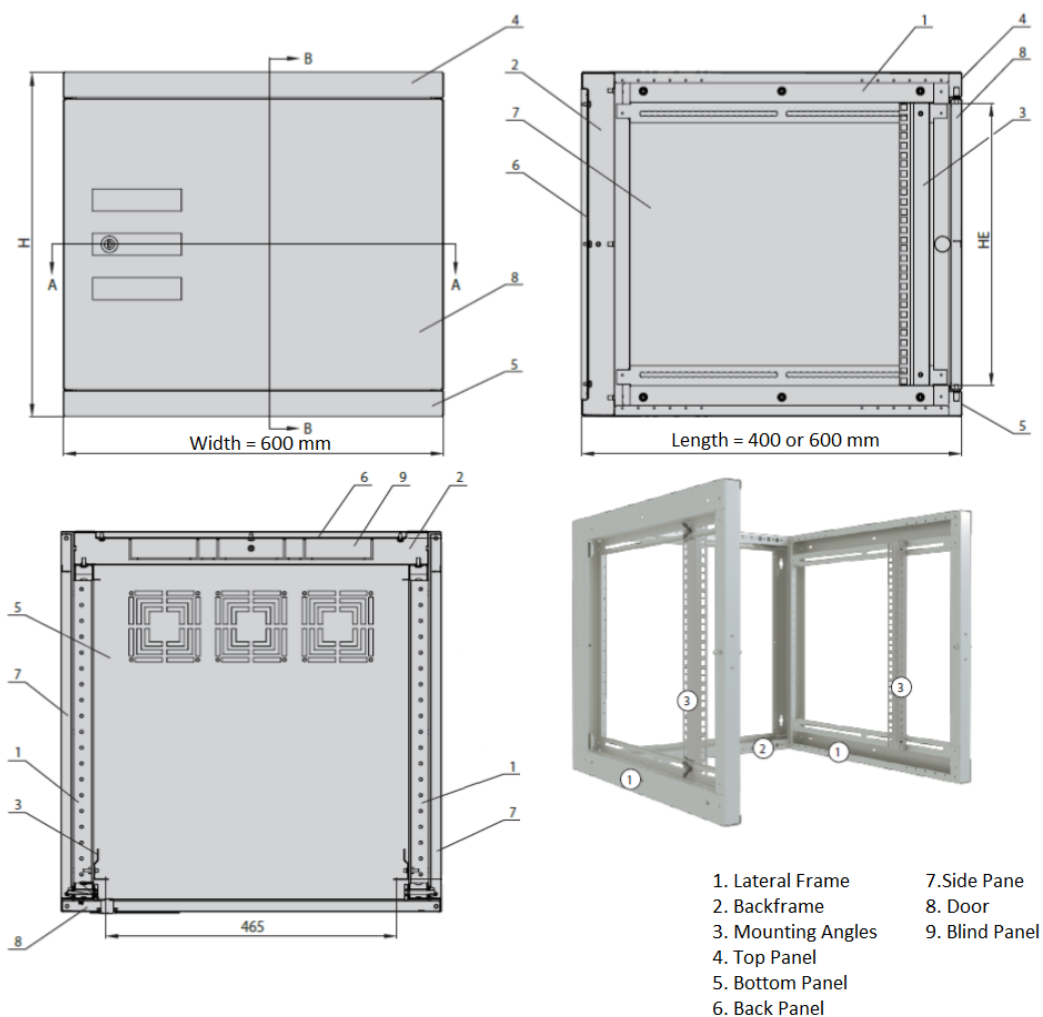

For more information and technical drawings, please contact us at [info@distrelec.com](mailto:info@distrelec.com).