


Butt Splice Connector

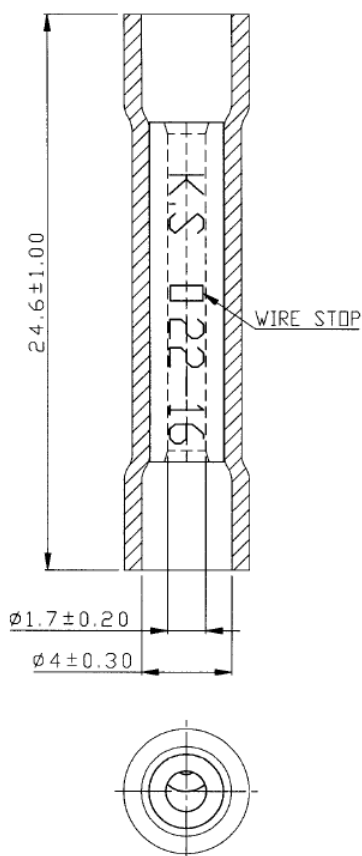

SPECIFICATION:

Material	Copper				
Wire Range	22-16 AWG (0.5...1.5 mm ²)				
Colour	Red				
Diameter	3.4 mm				
Insulation Material	Vinyl				
Voltage	600 V				
Surface material	Copper				
Temperature Range	max. +75 °C				
Plating	Tin				
Max. Electric Current	AWG	22	20	18	16
	A	9	12	17	18



Art. Nr.
RND 465-00097