

# Snipe Nose Pliers



## DESCRIPTION:

Snipe nose pliers for professionals with straight, smooth jaws

Special pliers made from high grade special steel for extremely high requirements

For gripping, bending and holding

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface

Ergonomically formed bicoloured hand guard - dissipative anti-slide material


The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

## SPECIFICATION:

|                    |        |
|--------------------|--------|
| Length             | 140 mm |
| A - Head width     | 10 mm  |
| B - Head length    | 32 mm  |
| C - Head thickness | 6.5 mm |
| D - Jaws thickness | 2 mm   |
| E - Jaws width     | 1 mm   |
| Weight             | 68 g   |

Art. Nr.

RND 550-00261

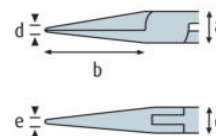

a=10mm/.394"  
b=32mm/1.260"  
c=6.5mm/.250"  
d=2mm/.079"  
e=1mm/.039"