

SMD Snipe Nose Pliers



DESCRIPTION:

SMD-Snipe nose pliers for professionals with straight, ultra thin smooth jaws, microfine pointed tips for very delicate work

Special pliers made from high grade special steel for extremely high requirements

For gripping, bending and holding

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface


Ergonomically formed bicoloured hand guard - dissipative anti-slide material

The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

SPECIFICATION:

Length	130 mm
A - Head width	10 mm
B - Head length	22 mm
C - Head thickness	6.5 mm
D - Jaws thickness	0.2 mm
E - Jaws width	0.1 mm
Weight	56 g

Art. Nr.
RND 550-00266

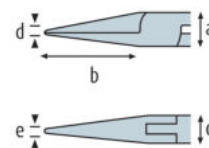

a=10mm/.394"
b=22mm/.866"
c=6.5mm/.250"
d=0.2mm/.0078"
e=0.1mm/.0039"