

# SMD Flat Nose Pliers



## DESCRIPTION:

SMD-Flat nose pliers for professionals with straight, very slim, smooth and short tapered jaws for very delicate work

Special pliers made from high grade special steel for extremely high requirements

For gripping, bending and holding

Box joint - double leaf spring

Precise jaw adjustment without backlash

High gloss steel polished surface


Ergonomically formed bicoloured hand guard - dissipative anti-slide material

The pliers have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas

## SPECIFICATION:

Length	130 mm
A - Head width	9 mm
B - Head length	22 mm
C - Head thickness	6 mm
D - Jaws thickness	1.2 mm
E - Jaws width	2.3 mm
Weight	58 g

Art. Nr.  
RND 550-00268

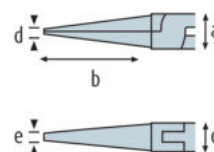

a=9mm/.354"  
b=22mm/.866"  
c=6mm/.236"  
d=1.2mm/.047"  
e=2.3mm/.091"