

Miniature Thermocouple Connector Plug & Socket



Features


- Miniature connector with rapid termination
- Easy jab-in connection
- Push-in wire & tighten screw



Specification

Thermocouple Type	K
Connector Size	Miniature
Connector Type	Quick Wire Plug & Socket
Colour	Yellow
Max. Temperature	220 °C
Pins	Flat Pins
+Positive Contact	NiCr
-Negative Contact	Ni
Standards Met	BS EN 50212:1997; RoHS

Drawing

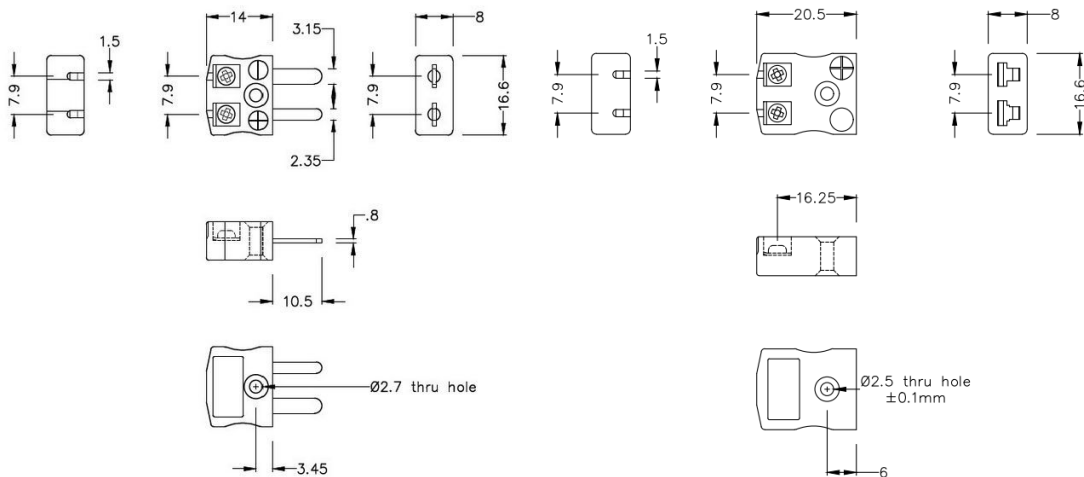

Miniature in-line Plug - Quick Wire
(dimensions in mm)

Miniature in-line Socket - Quick Wire
(dimensions in mm)

Art. Nr.
RND 410-00169