

Standard Quick Wire Thermocouple Connector Plug & Socket



Features


- Easy 'jab-in' connection for rapid termination
- Push wire in and tighten screw
- Contacts are polarised to prevent incorrect connection



Specification

Sensor Type	T
Connector Size	Standard
Connector Type	Quick Wire Plug & Socket
Colour	Brown
Max. Temperature	220 °C
Pins	Solid Round Pins
+Positive Contact	Cu
-Negative Contact	CuNi
Standards Met	BS EN 50212:1997; RoHS

Drawing

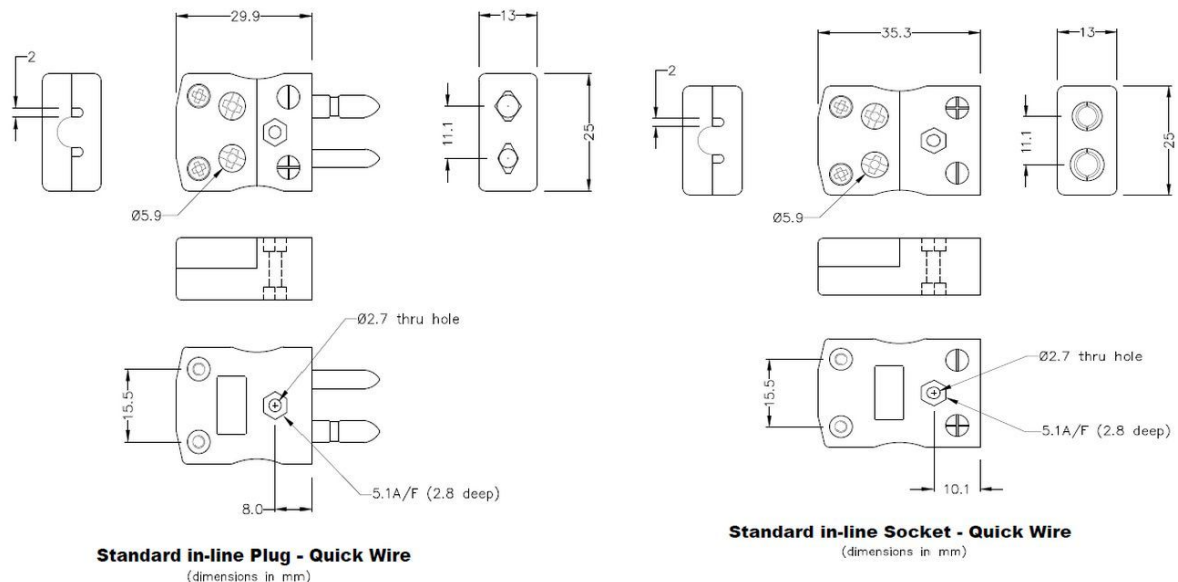

Art. Nr.
RND 410-00172