

Miniature Thermocouple Connector In-Line Socket



Features


- Ideal for general purpose use
- Contacts are polarised to ensure correct connection
- These connectors will accept thermocouple cable up to 4 mm in diameter



Specification

Sensor Type	K
Connector Size	Miniature
Connector Type	Socket
Colour	Yellow
Max. Temperature	220 °C
+Positive Contact	NiCr
-Negative Contact	NiAl
Standards Met	BS EN 50212:1997; RoHS

Drawing

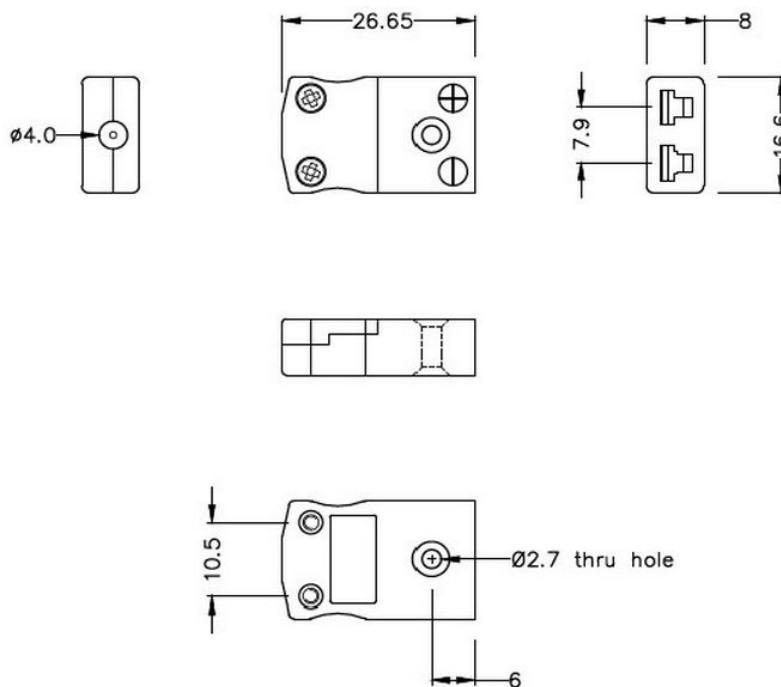

Miniature in-line Socket
(dimensions in mm)

Art. Nr.
RND 410-00176