

Miniature Panel Mount Thermocouple Connector



Features


- Miniature size sockets supplied with stainless steel brackets
- Allows quick, reliable, rugged fitting into panel
- Contacts are polarized to ensure correct connection



Specification

Thermocouple Type	J
Connector Size	Miniature
Connector Type	Quick Wire Socket with SS Bracket
Colour	Black
Max. Temperature	220 °C
Pins	Flat Pins
+Positive Contact	Fe
-Negative Contact	CuNi
Standards Met	BS EN 50212:1997; RoHS

Drawing

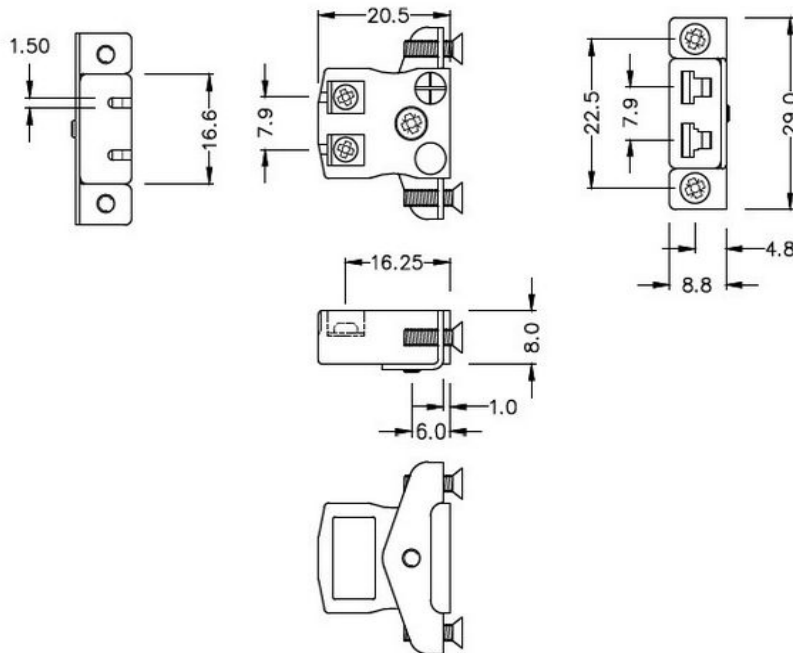

**Miniature Socket -
Quick Wire with stainless steel mounting bracket**
(dimensions in mm)

Art. Nr.
RND 410-00186