

# Standard Panel Mount Thermocouple Connector



## Features


- The thermocouple connector is equipped with a robust stainless steel bracket, providing excellent corrosion resistance and ensuring long-lasting performance in harsh industrial environments
- This ensures stable and consistent connections, even in environments with high levels of vibration or movement
- This makes it suitable for a wide range of industrial applications where precise temperature measurements are crucial



## Specification

Sensor Type	T
Connector Size	Standard
Connector Type	Socket with SS Bracket
Colour	Brown
Max. Temperature	220°C
+Positive Contact	Cu
-Negative Contact	CuNi
Standards Met	BS EN 50212:1997; RoHS

## Drawing

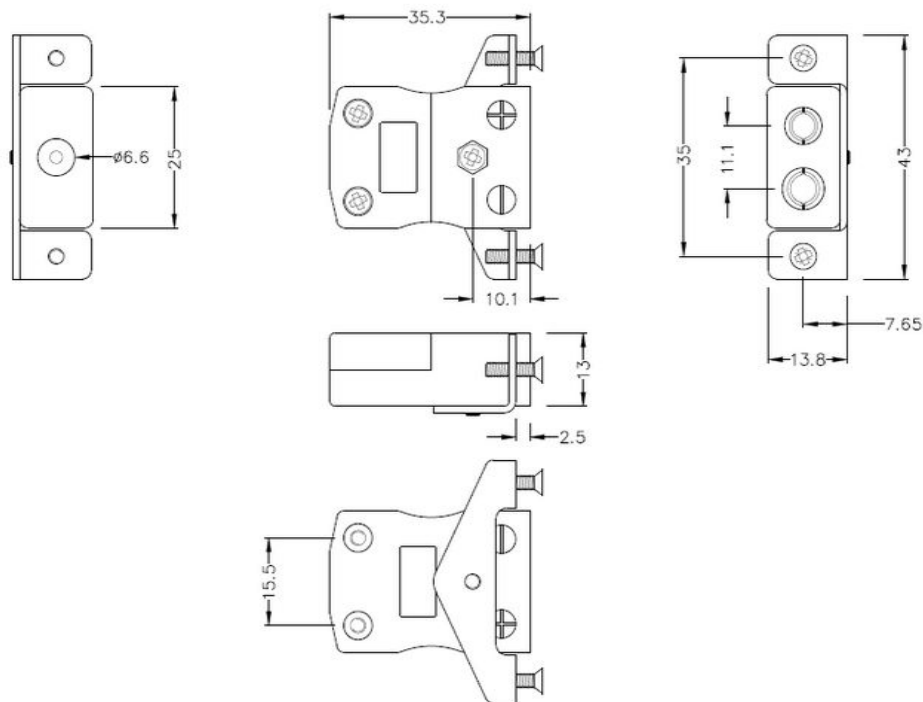

**Standard in-line Socket with stainless steel mounting bracket**  
(dimensions in mm)

Art. Nr.  
RND 410-00221