

Split ferrite

$\varnothing \leq 6.5 \text{ mm}$





FEATURES:

Square Shape

SPECIFICATION:

For cable size	$\varnothing \leq 6.5 \text{ mm}$
Colour	black
A	20.5 mm
B	20 mm
C	6.5 mm
D	33 mm
Impedance @ 25 MHz	135 Ω
Impedance @ 100 MHz	220 Ω

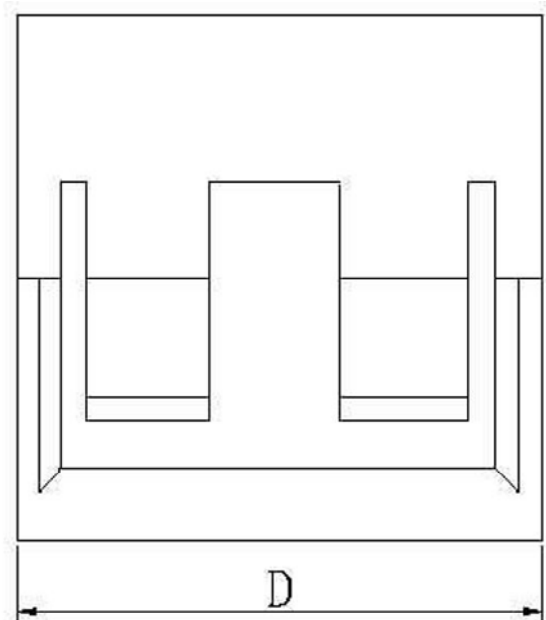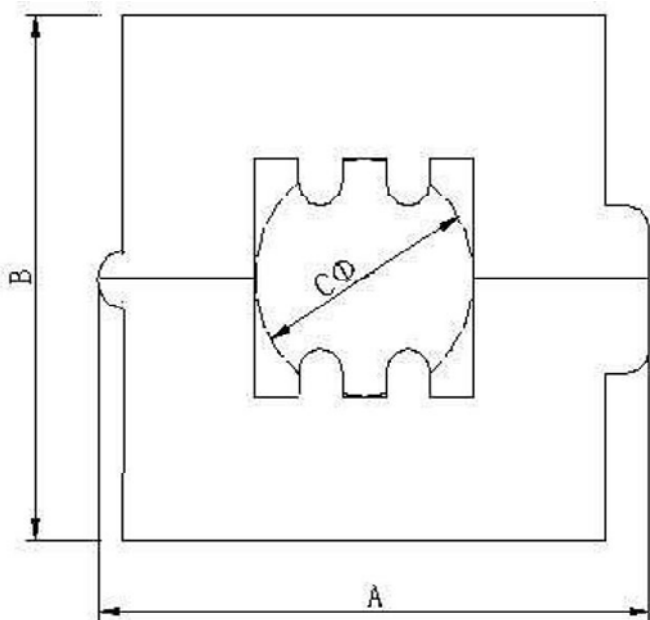


Split ferrite

$\varnothing \leq 6.5 \text{ mm}$



Frequency Graph

1. TEST INSTRUMENT: HP4286A
2. WINDING: $0.8 \Phi \times 220 \text{ mm}$ 2 U. E. W 1 TS

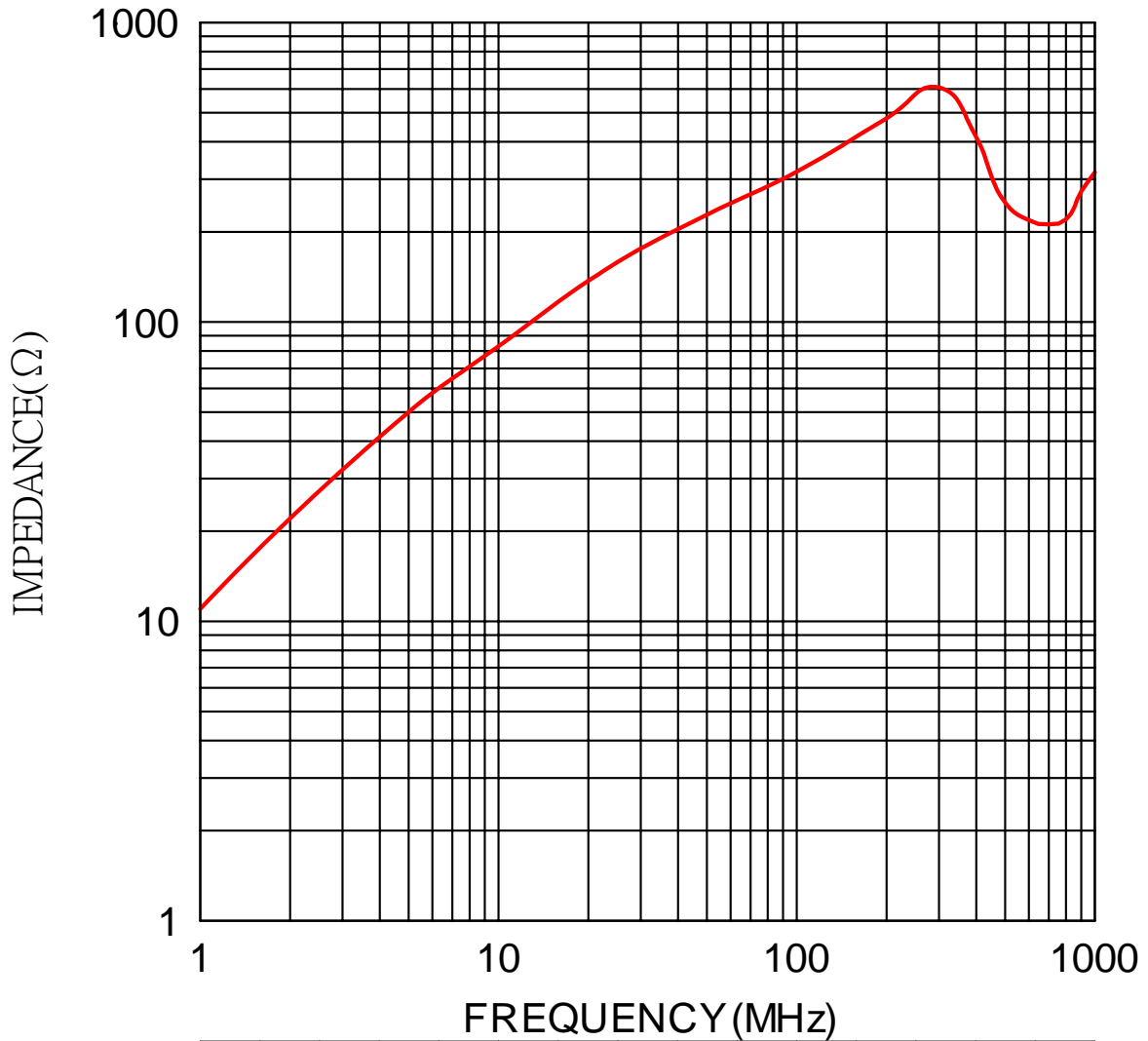

	1	5	10	25	50	100	200	300	400	500	600	700	800	900	1000
Z	11	50	83	158	228	318	479	607	414	251	219	212	220	273	316

(DATA BETWEEN 500MHz AND 1000MHz ARE FOR REFERENCE ONLY)

Art. Nr.
RND 165-00001