

Split ferrite


$\varnothing \leq 13$ mm

FEATURES:

Round Shape

SPECIFICATION:

For cable size	$\varnothing \leq 13$ mm
Colour	Grey
A	31.5 mm
B	30.5 mm
C	13 mm
D	34 mm
E	39 mm
Impedance @ 100 MHz	130 Ω

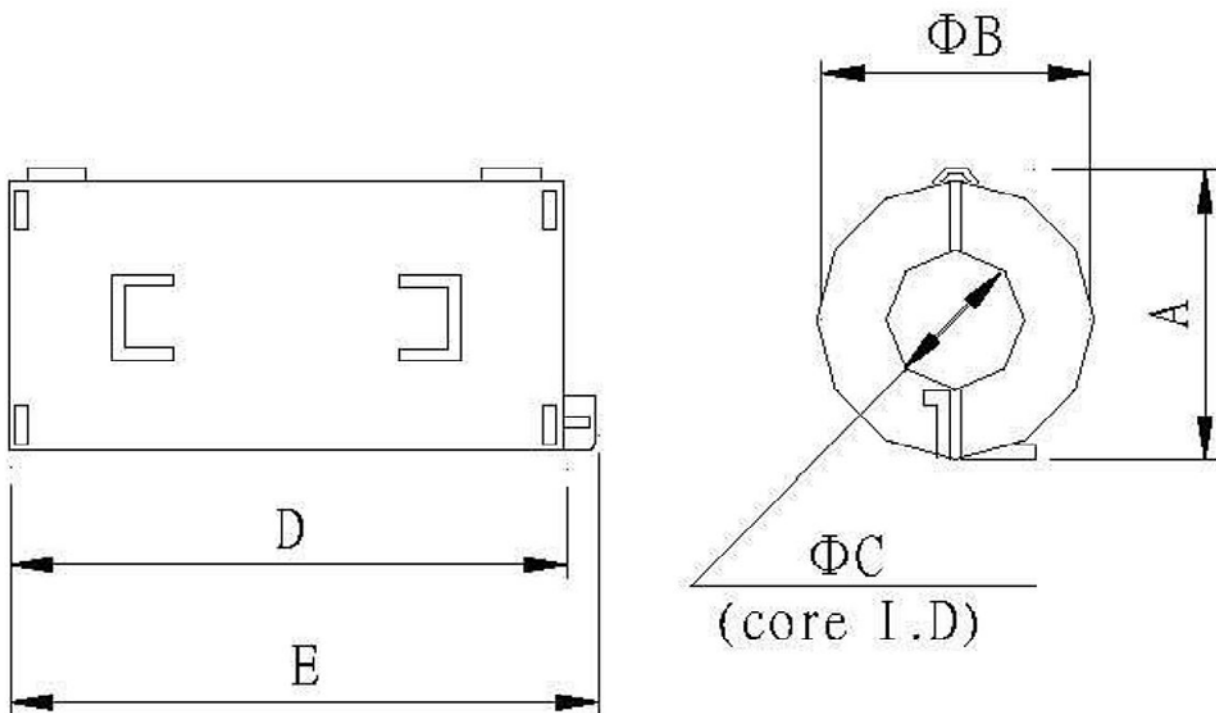


Split ferrite

$\varnothing \leq 13 \text{ mm}$



Frequency Graph

- 1. TEST INSTRUMENT: HP4286A
- 2. WINDING: 0.8 Φ X 200 mm 2 U. E. W 1 TS

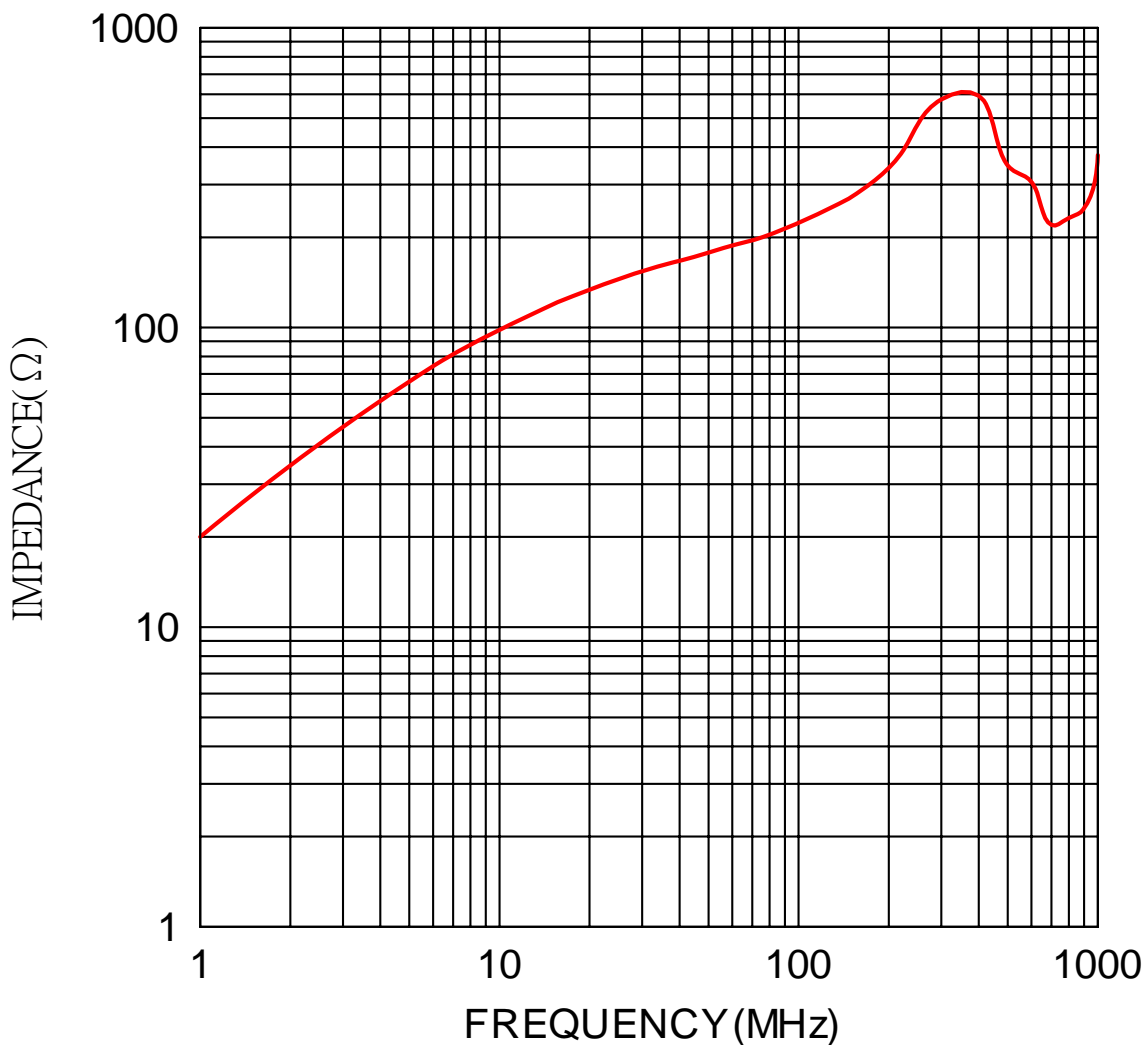

	1	5	10	25	50	100	200	300	400	500	600	700	800	900	1000
Z	20	66	98	145	178	224	341	577	594	347	306	220	232	250	376

(DATA BETWEEN 500MHz AND 1000MHz ARE FOR REFERENCE ONLY)

Art. Nr.
RND 165-00002