

Split ferrite

$\varnothing \leq 10 \text{ mm}$





FEATURES:

Square Shape

SPECIFICATION:

For cable size	$\varnothing \leq 10 \text{ mm}$
Colour	black
A	25.5 mm
B	23.5 mm
C	10 mm
D	33 mm
Impedance @ 25 MHz	110 Ω
Impedance @ 100 MHz	180 Ω

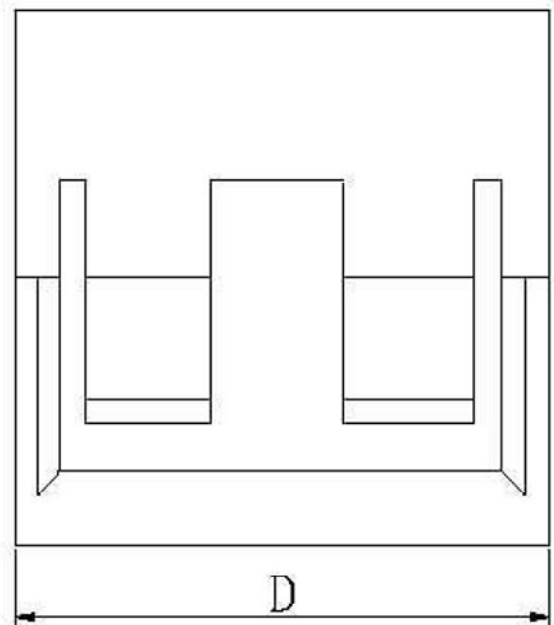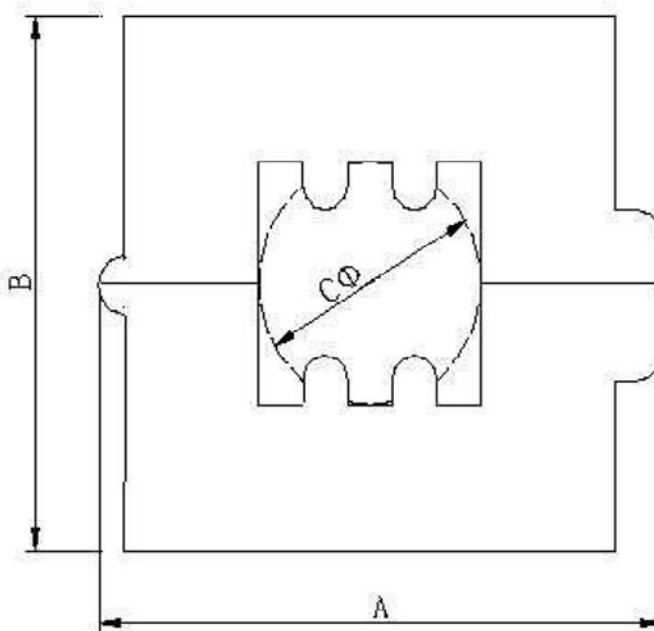


Split ferrite

$\varnothing \leq 10 \text{ mm}$

Frequency Graph

1. TEST INSTRUMENT: HP4286A
2. WINDING: 0.8 Φ X 220 mm 2 U. E. W 1TS

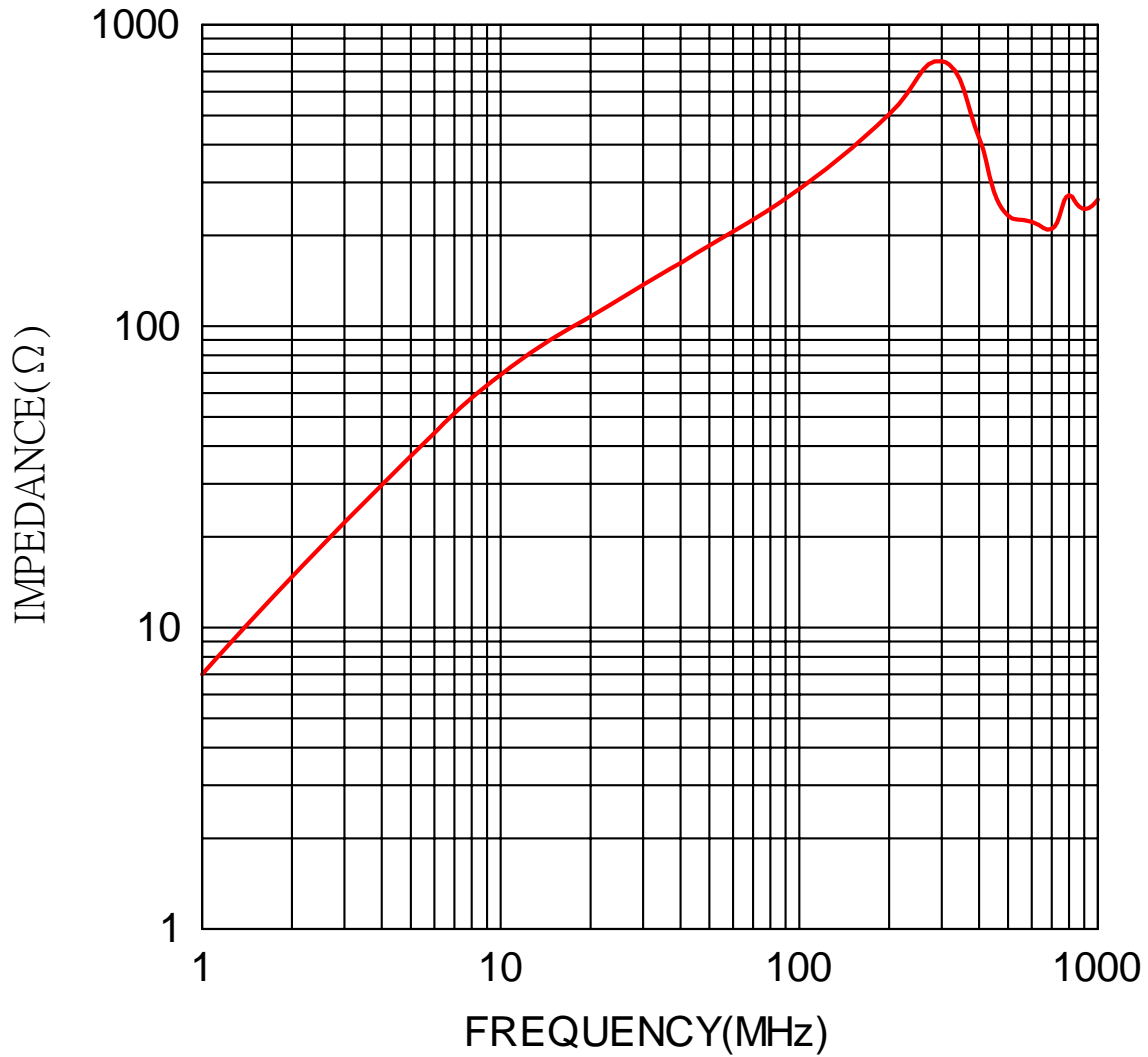

	1	5	10	25	50	100	200	300	400	500	600	700	800	900	1000
Z —	7	37	69	123	185	286	505	757	421	233	222	210	272	245	263

(DATA BETWEEN 500MHz AND 1000MHz ARE FOR REFERENCE ONLY)

Art. Nr.
RND 165-00009