

Split ferrite



$\varnothing \leq 13 \text{ mm}$

FEATURES:

Square Shape

SPECIFICATION:

For cable size	$\varnothing \leq 13 \text{ mm}$
Colour	black
A	31.5 mm
B	30 mm
C	13 mm
D	33 mm
Impedance @ 25 MHz	151 Ω
Impedance @ 100 MHz	270 Ω

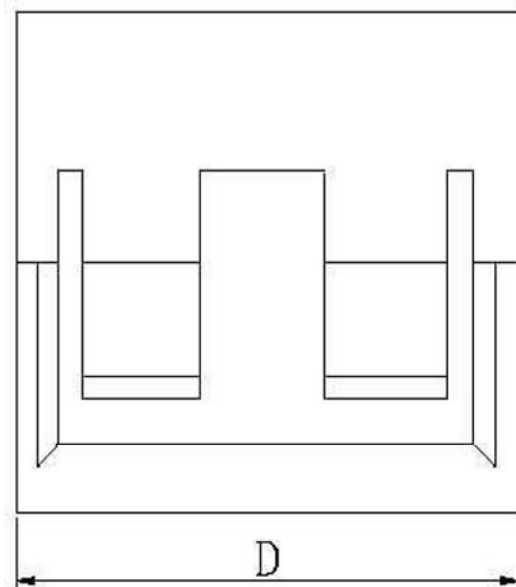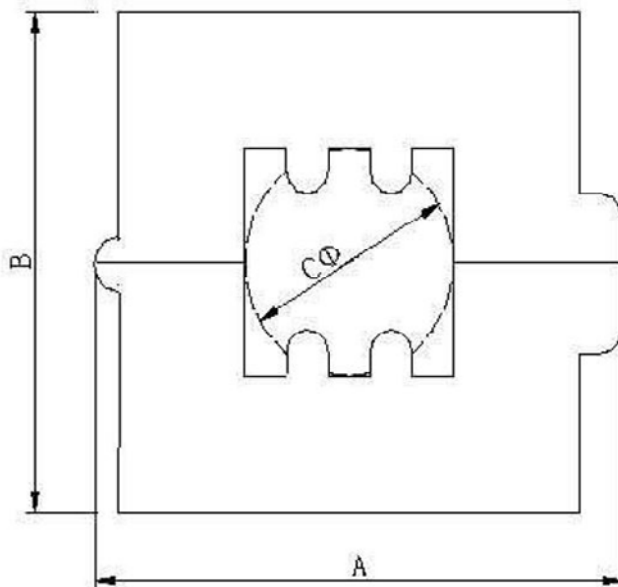


Split ferrite

$\varnothing \leq 13 \text{ mm}$



Frequency Graph

1. TEST INSTRUMENT: HP4286A
2. WINDING: 0.4 Φ X165 mm 2 U. E. W 1TS

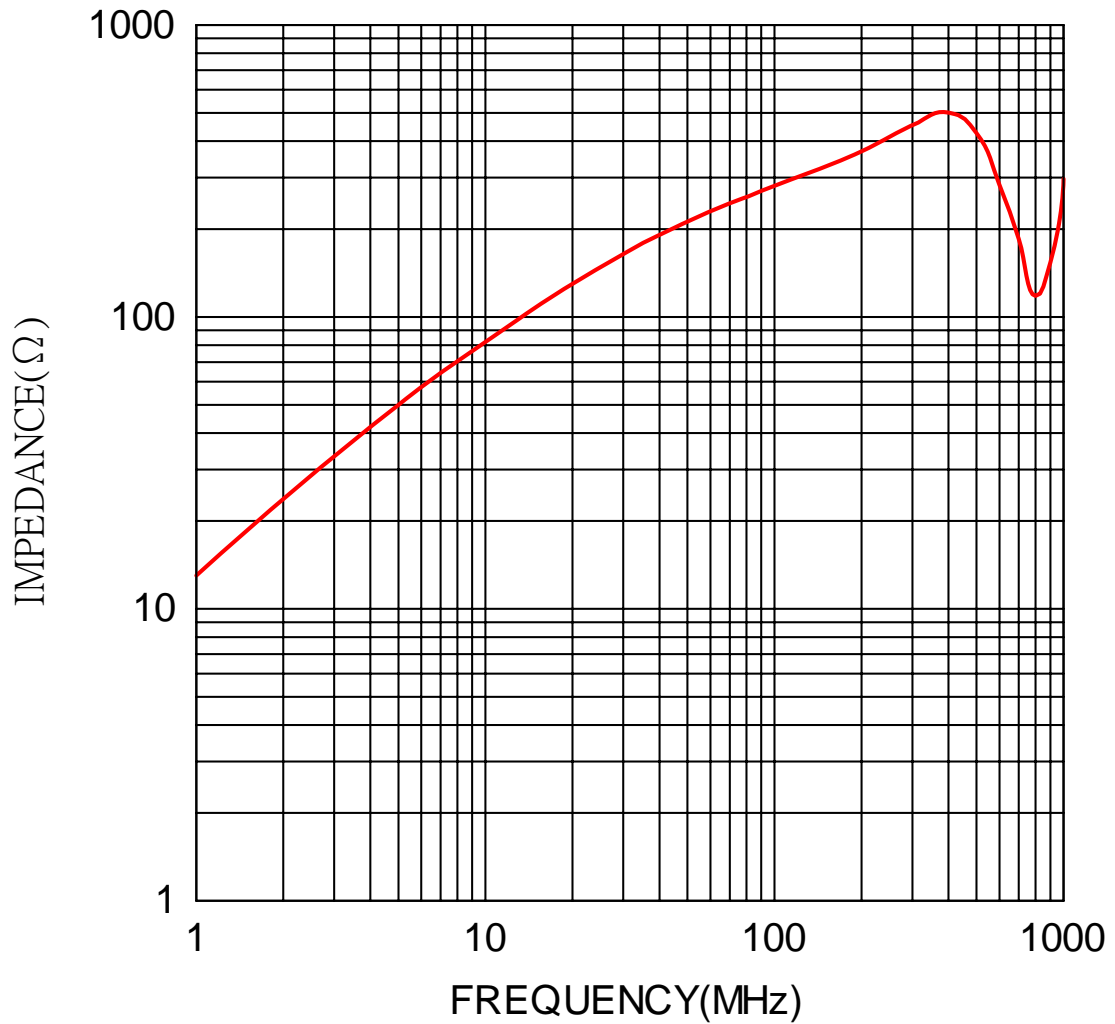

	1	5	10	25	50	100	200	300	400	500	600	700	800	900	1000
Z —	13	50	82	148	212	281	369	453	501	426	283	185	118	154	297

(DATA BETWEEN 500MHz AND 1000MHz ARE FOR REFERENCE ONLY)

Art. Nr.
RND 165-00011