



EMI Filter

SPECIFICATION:

Length	85 mm
Height	51 mm
IEC-climate category	25/085/21
Leakage current	2 mA @ 250 VAC/50 Hz
Rated current	20 A
Rated voltage	250 VAC
Max. temperature	+85 °C
Min. Temperature	-25 °C
Resistance	50 MΩ
Width	38 mm

Art. Nr.

RND 165-00031

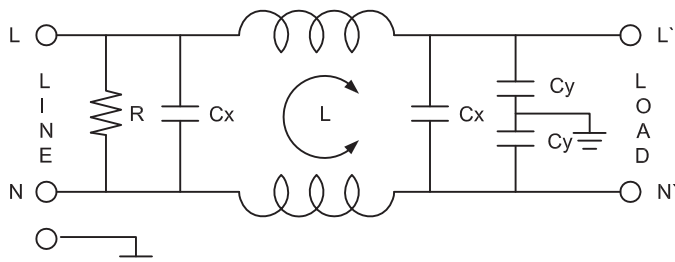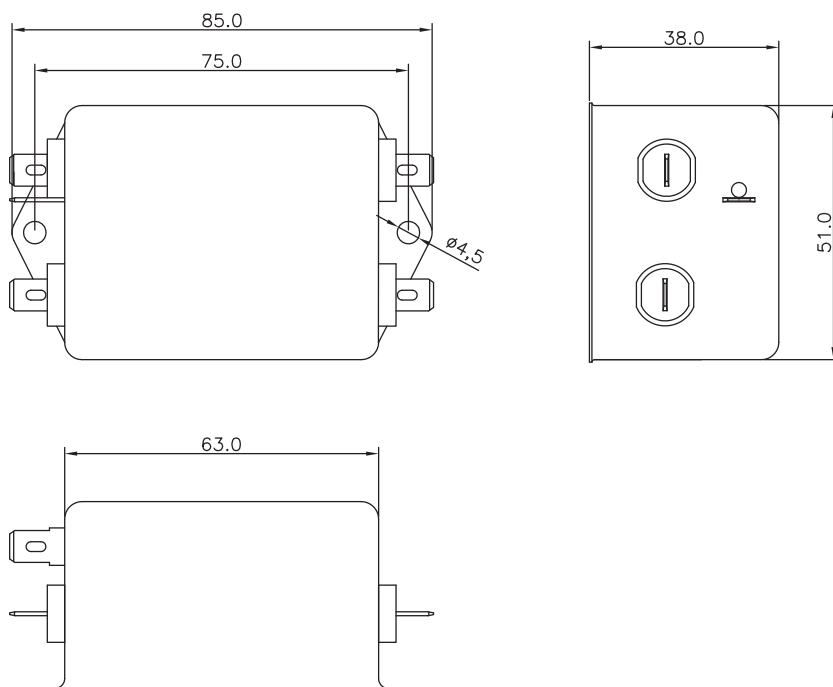

L: 2x4.0mH
Cx: 0.1 μ F(X2)
Cy: 10000pF(Y2)
R: 680K ohm