

## Features

- Excellent EMI suppression
- Light weight
- Precision formed smooth surfaces prevent damage to wire insulation
- For retrofit and post-assembly operations

## Applications


- Internal and external power cables
- Computer peripherals
- Digital TVs, TV monitors and printers



## Specification


For Cable Size	$\varnothing \leq 6.5$ mm
Impedance @ 100 MHz	100 $\Omega$
Impedance @ 25 MHz	65 $\Omega$
Shape	Round
Combustibility Class	UL 94 V-0
Openable	Yes
Colour	Grey

## Drawing

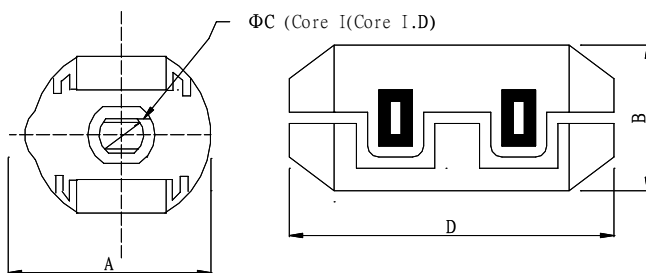

A	$20.0 \pm 1$ mm
B	$18.0 \pm 1$ mm
C	$6.50 \pm 1$ mm
D	$36.0 \pm 1$ mm

## Z-F Response

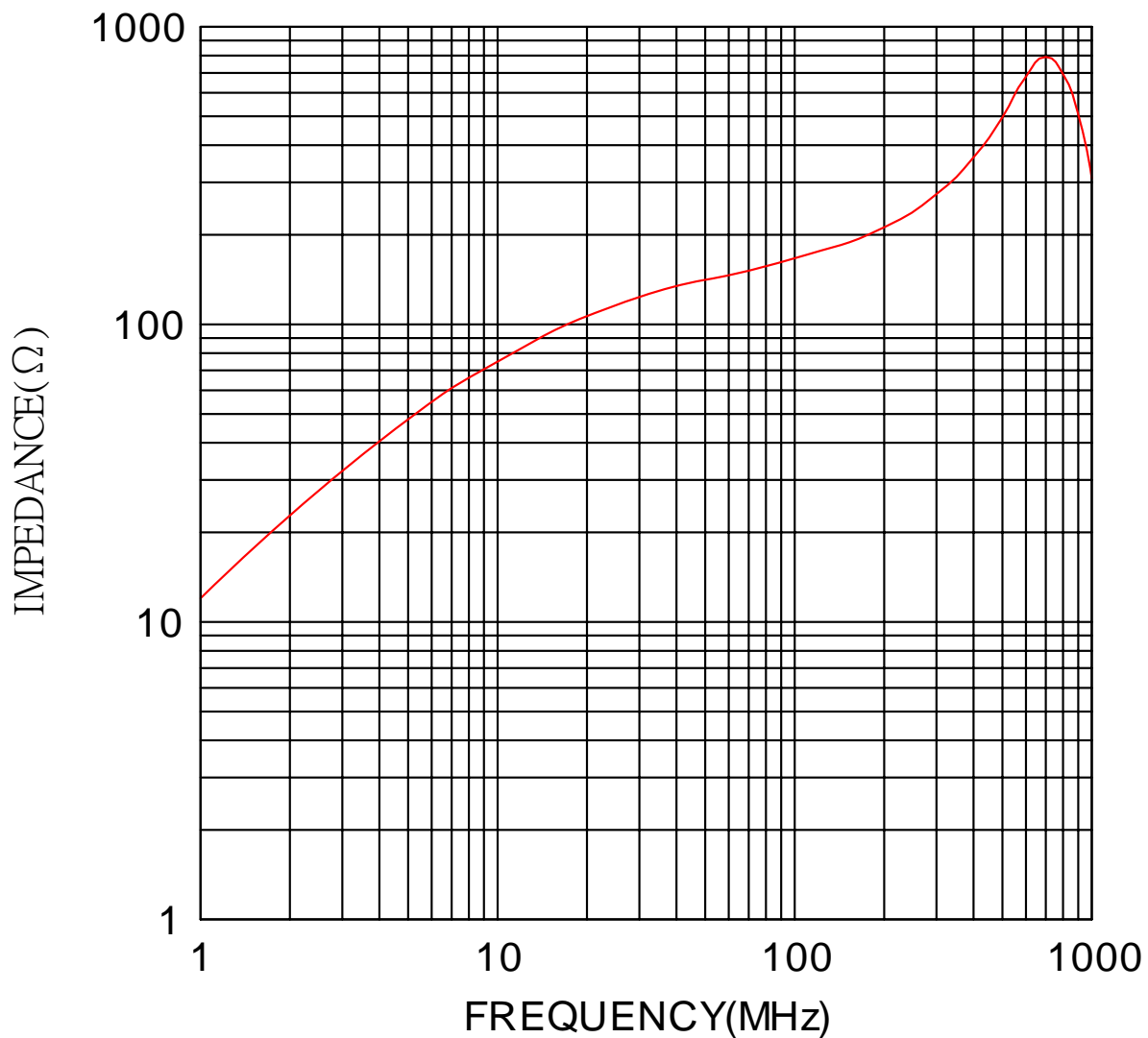

	1	5	10	25	100	200	300	400	500	600	700	800	900	1000
Z —	12	48	75	116	167	212	274	364	497	680	792	693	506	309

**Art Nr.**  
**RND 165-00248**