

DIP Plug


6P



FEATURES:

SPECIFICATION:

| | |
|----------------------|---|
| Poles | 6 |
| Pitch | 2.54 mm |
| Rated current | 1 A |
| Housing Material | Glass fibre (GF)/Polybutylene terephthalate (PBT) |
| Contact material | Copper alloy |
| Test voltage | 0.5 kV |
| Temperature range | -40...+105 °C |
| Combustibility class | UL 94 V-0 |
| A | 13.07 mm |
| B | 6.35 mm |
| C | 5.08 mm |

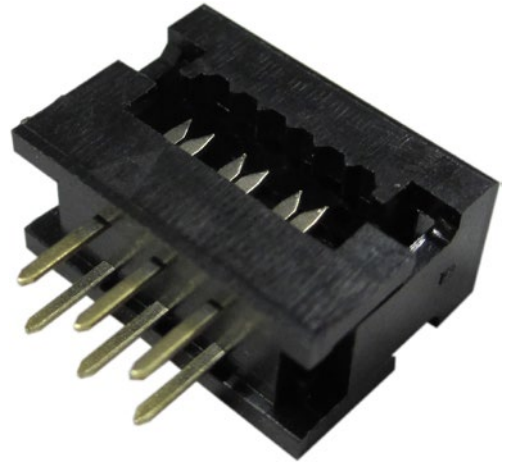

Art. Nr.

RND 205-00688

