

# DIP Ribbon Cable Plug


## 10P



### FEATURES:

#### SPECIFICATION:

Poles	10
Pitch	2.54 mm
Rated current	1 A
Housing Material	Glass fibre (GF)/Polybutylene terephthalate (PBT)
Contact material	Copper alloy
Test voltage	0.5 kV
Temperature range	-40...+105 °C
Combustibility class	UL 94 V-0
A	18.15 mm
B	11.43 mm
C	10.16 mm

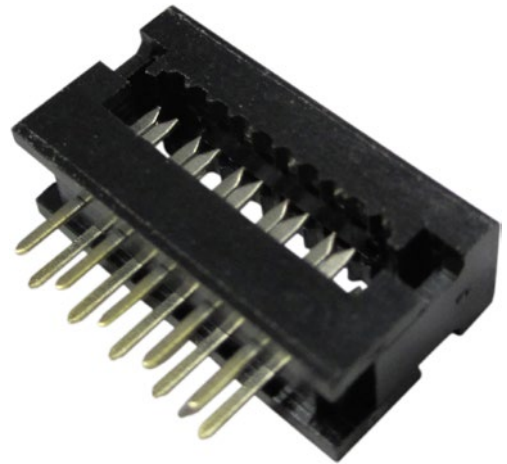

Art. Nr.

RND 205-00690

