

DIP Ribbon Cable Plug


12P



FEATURES:

SPECIFICATION:

Poles	12
Pitch	2.54 mm
Rated current	1 A
Housing Material	Glass fibre (GF)/Polybutylene terephthalate (PBT)
Contact material	Copper alloy
Test voltage	0.5 kV
Temperature range	-40...+105 °C
Combustibility class	UL 94 V-0
A	20.69 mm
B	13.97 mm
C	12.7 mm

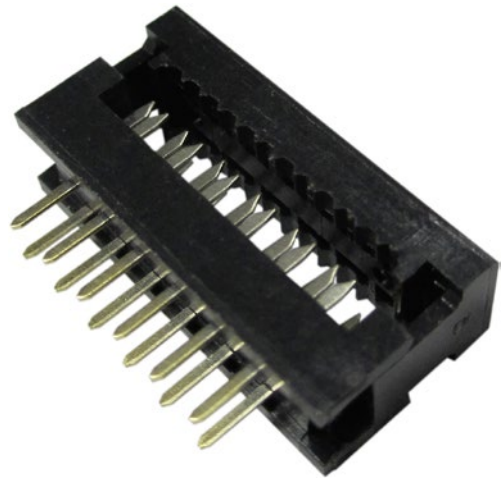

Art. Nr.

RND 205-00691

