

# D-Sub Crimp Connector

## 25P, Female



### SPECIFICATION:

Poles	25
Termination	Straight/Crimp
Rows	2
Gender of contacts	Female
A	53.05 mm
B	47.05 mm
C	38.3 mm
Colour	Black
D	12.5 mm
E	7.9 mm
Housing Material	Steel
Insulator material	PBT
Outside material	Metal
Temperature range	-55...+105 °C
Rated current	3 A
Dielectric strength	1000 MΩ
Rated voltage	125 V
Proof voltage	1000 VAC


### Art. Nr.

**RND 205-00743**

Associated pin contacts:

[30108938, RND 205-00787, Crimp Contacts, Female, 18...22 AWG](#)

[30108939, RND 205-00788, Crimp Contacts, Female, 24...26 AWG](#)

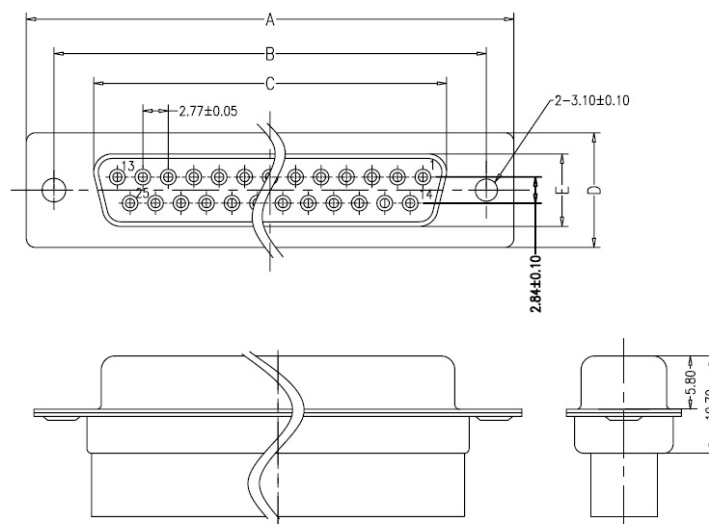

RND Part Number	A±0.35	B±0.25	C±0.25	D±0.25	E±0.10
RND 205-00741	30.80	25.00	16.30	12.50	7.90
RND 205-00742	39.20	33.30	24.60	12.50	7.90
RND 205-00743	53.05	47.05	38.30	12.50	7.90
RND 205-00744	69.40	63.50	54.80	12.50	7.90