

D-Sub Connector

9P, Male






SPECIFICATION:

| | |
|--------------------|---------------------|
| Poles | 9 |
| Terminatio | 180°/Solder PCB THT |
| Gender of contacts | Male |
| A | 30.8 mm |
| B | 25 mm |
| C | 16.9 mm |
| Colour | Black |
| Contact material | Brass, Gold-Flashed |
| D | 12.5 mm |
| E | 8.3 mm |
| Housing Material | Steel/Nickel (Ni) |
| Insulator material | PBT |
| Outside material | Metal |
| Rated current | 3 A |
| Temperature range | -55...+105 °C |

Art. Nr.

RND 205-00778

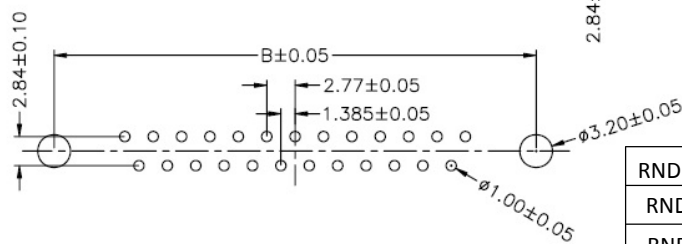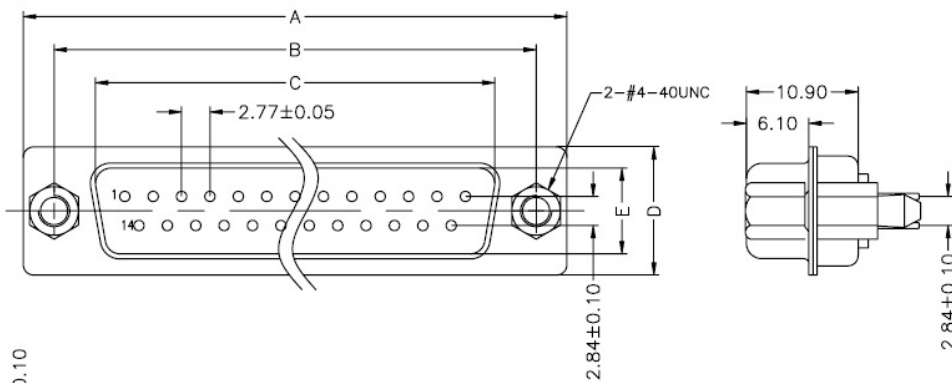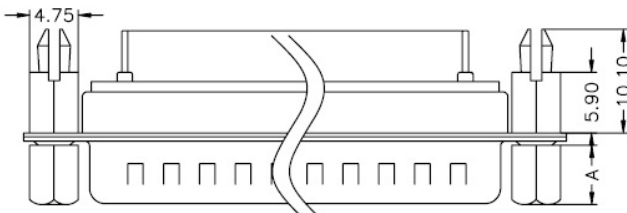

| RND Part Number | A±0.35 | B±0.25 | C±0.25 | D±0.25 | E±0.20 |
|-----------------|--------|--------|--------|--------|--------|
| RND 205-00778 | 30.80 | 25.00 | 16.90 | 12.50 | 8.30 |
| RND 205-00780 | 39.20 | 33.30 | 25.25 | 12.50 | 8.30 |
| RND 205-00782 | 53.05 | 47.05 | 38.95 | 12.50 | 8.30 |
| RND 205-00784 | 69.40 | 63.50 | 55.40 | 12.50 | 8.30 |