

D-Sub Gender Changer

9P, Female / Female








SPECIFICATION:


| | |
|------------------------------|----------------------------------|
| Poles | 9 |
| Insulator | PBT, UL 94 V-0 |
| Gender of contacts | Female / Female |
| Connection A | D-SUB 9-Pin Female |
| Connection B | D-SUB 9-Pin Female |
| Housing material | Steel |
| Temperature range | -55...+105 °C |
| Rated current | 3 A |
| Contact material | Brass, gold-plated |
| Dielectric withstand voltage | AC 1000 V RMS |
| Insulation resistance | 1000 M Ω min. at DC 500 V |
| Contact resistance | 25 m Ω max. |

Art. Nr.

RND 205-00849

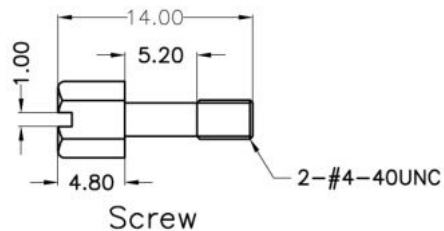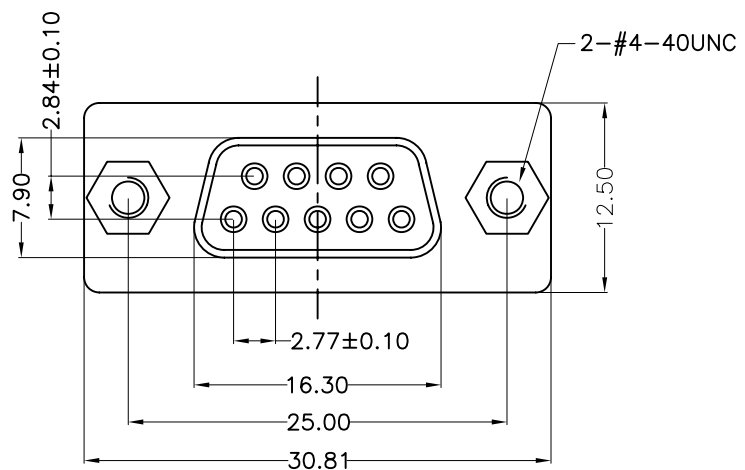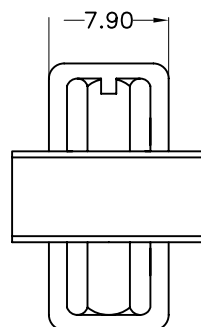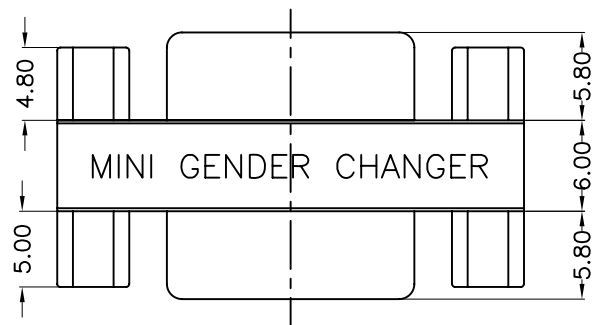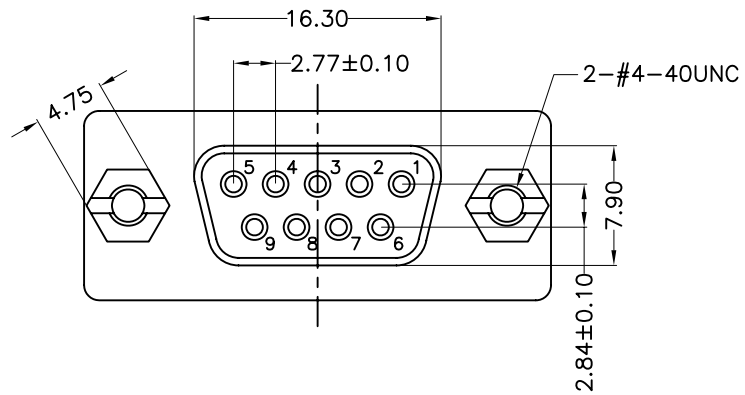

DGC 09F/F GENDER CHANGER
 PIN OUT: 9Female 9Female

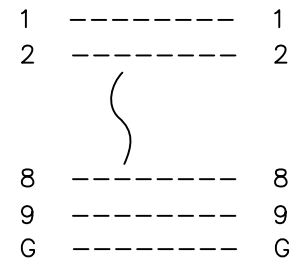

Label: Yellow Color With Black Character.
 One Side: MINI GENDER CHANGER.
 The Other Side: U.S.A PATENT 5199906