

D-Sub Gender Changer



15P, Female / Female




SPECIFICATION:

Poles	15
Insulator	PBT, UL 94 V-0
Gender of contacts	Female / Female
Connection A	D-SUB 15-Pin Female
Connection B	D-SUB 15-Pin Female
Housing material	Steel
Temperature range	-55...+105 °C
Rated current	3 A
Contact material	Brass, gold-plated
Dielectric withstand voltage	AC 1000 V RMS
Insulation resistance	500 MΩ min. at DC 500 V
Contact resistance	25 mΩ max.

Drawing

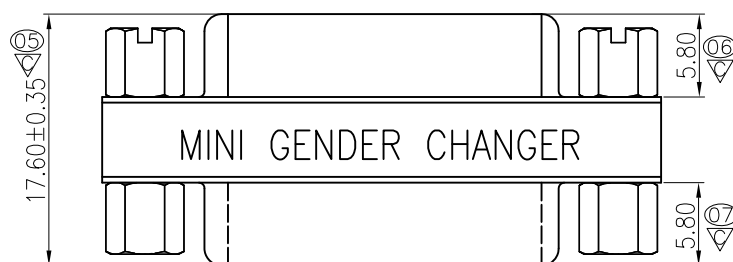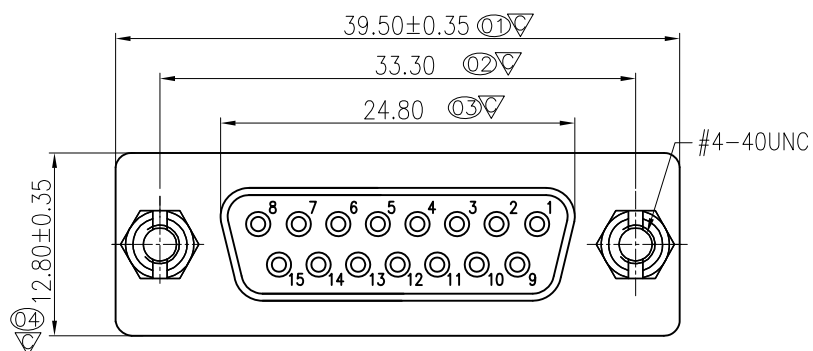

15Female		15Female
1	-----	1
2	-----	2
	}	
14	-----	14
15	-----	15
shell	-----	shell

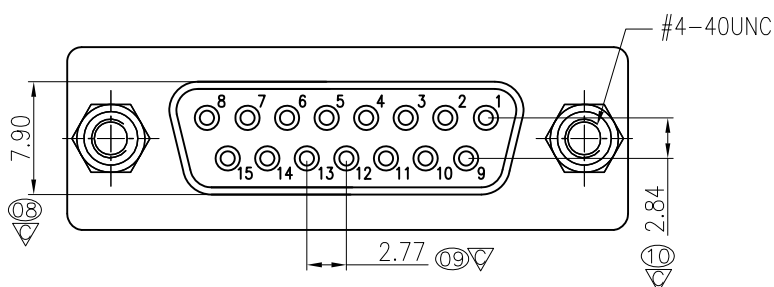

Art. Nr.

RND 205-00850