

D-Sub Gender Changer

25P, Female / Female






SPECIFICATION:

Poles	25
Insulator	PBT, UL 94 V-0
Gender of contacts	Male / Male
Connection A	D-SUB 25-Pin Female
Connection B	D-SUB 25-Pin Female
Housing material	Steel
Temperature range	-55...+105 °C
Rated current	3 A
Contact material	Brass, gold-plated
Dielectric withstand voltage	AC 1000 V RMS
Insulation resistance	1000 MΩ min. at DC 500 V
Contact resistance	25 mΩ max.

Art. Nr.

RND 205-00851

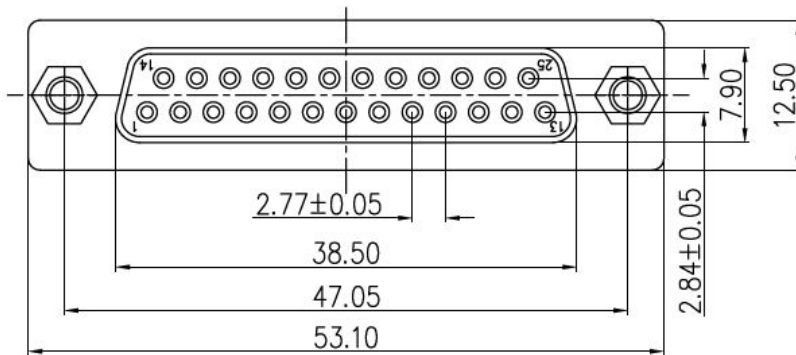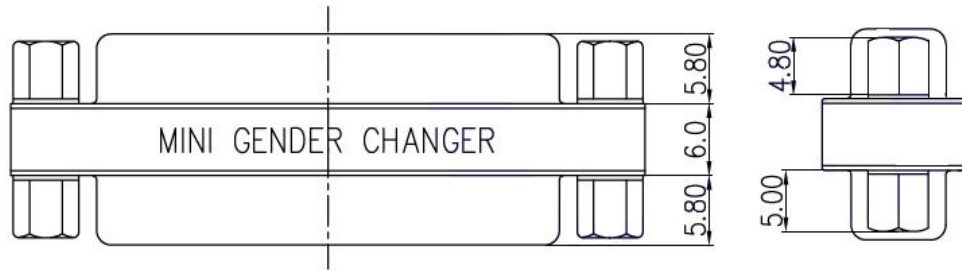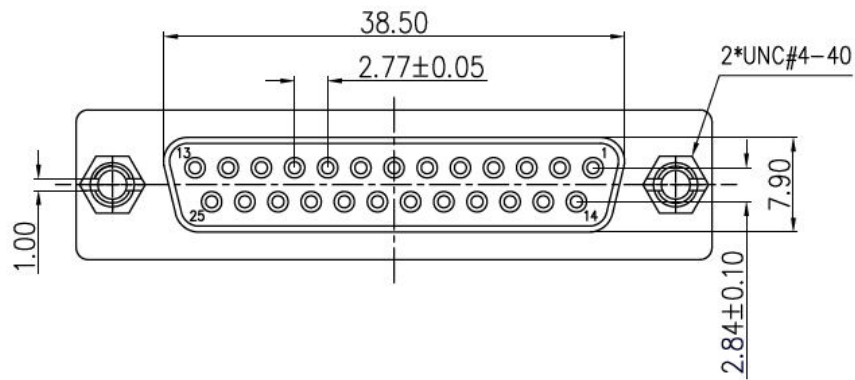

DGC 25F/F GENDER CHANGER

PIN OUT: 25Female 25Female

1 ----- 1
2 ----- 2

24 ----- 24
25 ----- 25
G ----- G

Label: Yellow Color With Black Charactor.
One Side: MINI Gender Changer.
The Other Side: U.S.A Patent 5199906