

D-Sub Gender Changer

25P, Male / Male






SPECIFICATION:

Poles	25
Insulator	PBT, UL 94 V-0
Gender of contacts	Male / Male
Connection A	D-SUB 25-Pin Male
Connection B	D-SUB 25-Pin Male
Housing material	Steel
Temperature range	-55...+105 °C
Rated current	3 A
Contact material	Brass, gold-plated
Dielectric withstand voltage	AC 1000 V RMS
Insulation resistance	1000 MΩ min. at DC 500 V

Art. Nr.

RND 205-00854

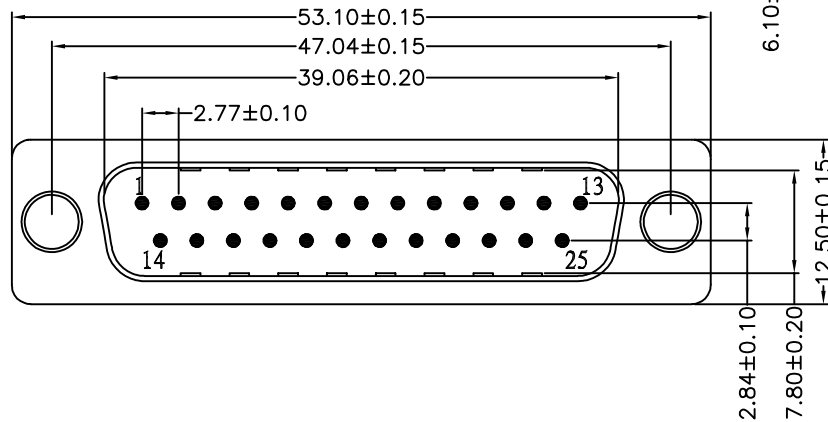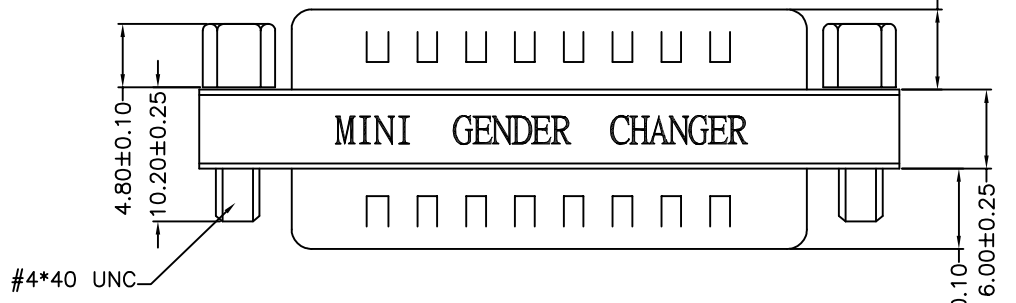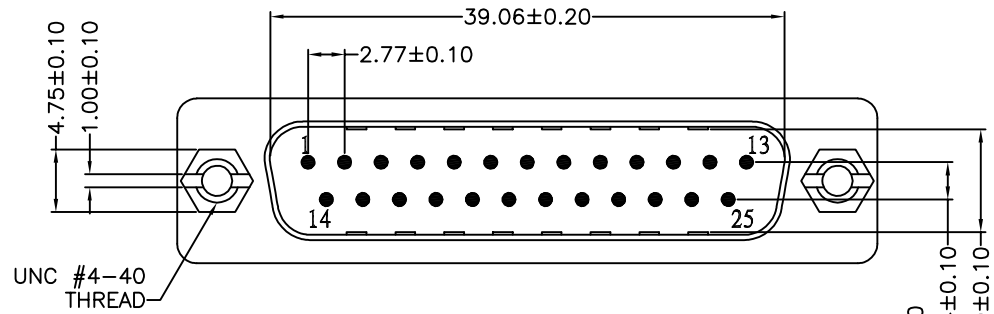

DGC 25M/M GENDER CHANGER
 PIN OUT: 25Male 25Male

