


USB 2.0 - A Connector

Features


- Male
- Angled mounting type
- Low heavy metal
- 8 flash
- Black insulator colour
- 0

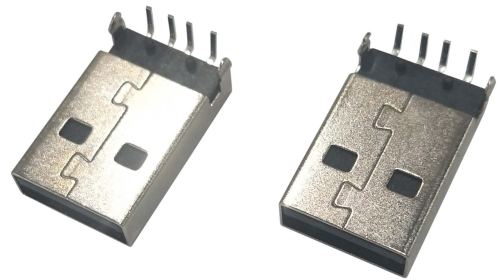

Specification

Contact Material	Brass
Insulator Material	PBT, UL 94V-0
Shell Material	SPCC
Current Rating	1.5 A
Contact Resistance	30 mOhm max.
Insulation Resistance @ 500 VDC	1000 MOhm min.
Dielectric Withstanding Voltage	500 VAC
Operating Temperature Min.	-55 °C
Operating Temperature Max.	85 °C

Drawing

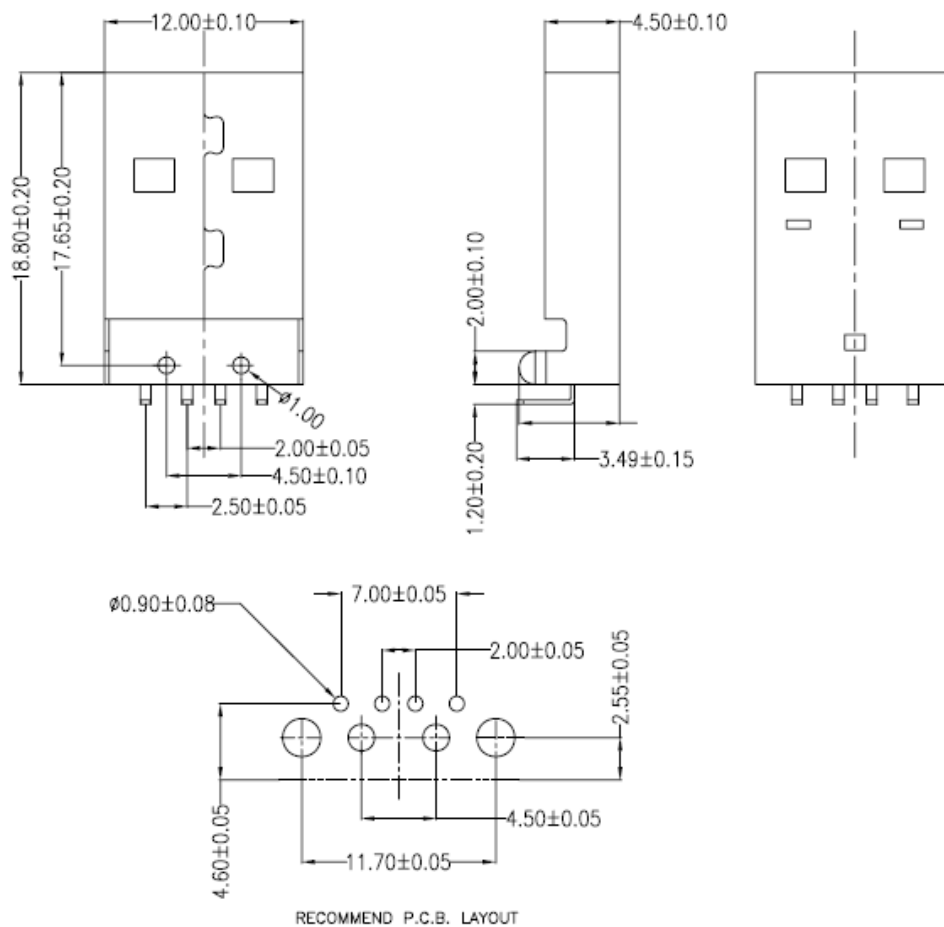

Art Nr:

RND 205-01044