


Mini USB 2.0 - AB Connector

Features


- Female
- Angled mounting type
- Low heavy metal
- 8 flash
- Black insulator colour
- 0

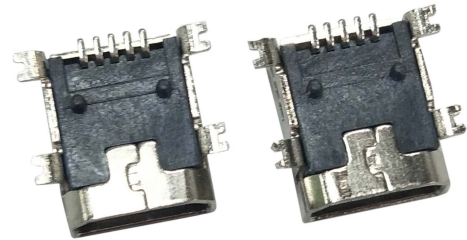

Specification

Insulator Material	LCP+Glass, UL-94V-0
Contact Material	Brass
Shell Material	Copper Alloy
Current Rating	1 A
Contact Resistance (Low Level)	50 mOhm max.
Insulation Resistance	100 MOhm min. @ 500 VDC
Dielectric Withstanding Voltage	100 VAC for 1 min.
Operating Temperature Min.	-55 °C
Operating Temperature Max.	85 °C

Drawing

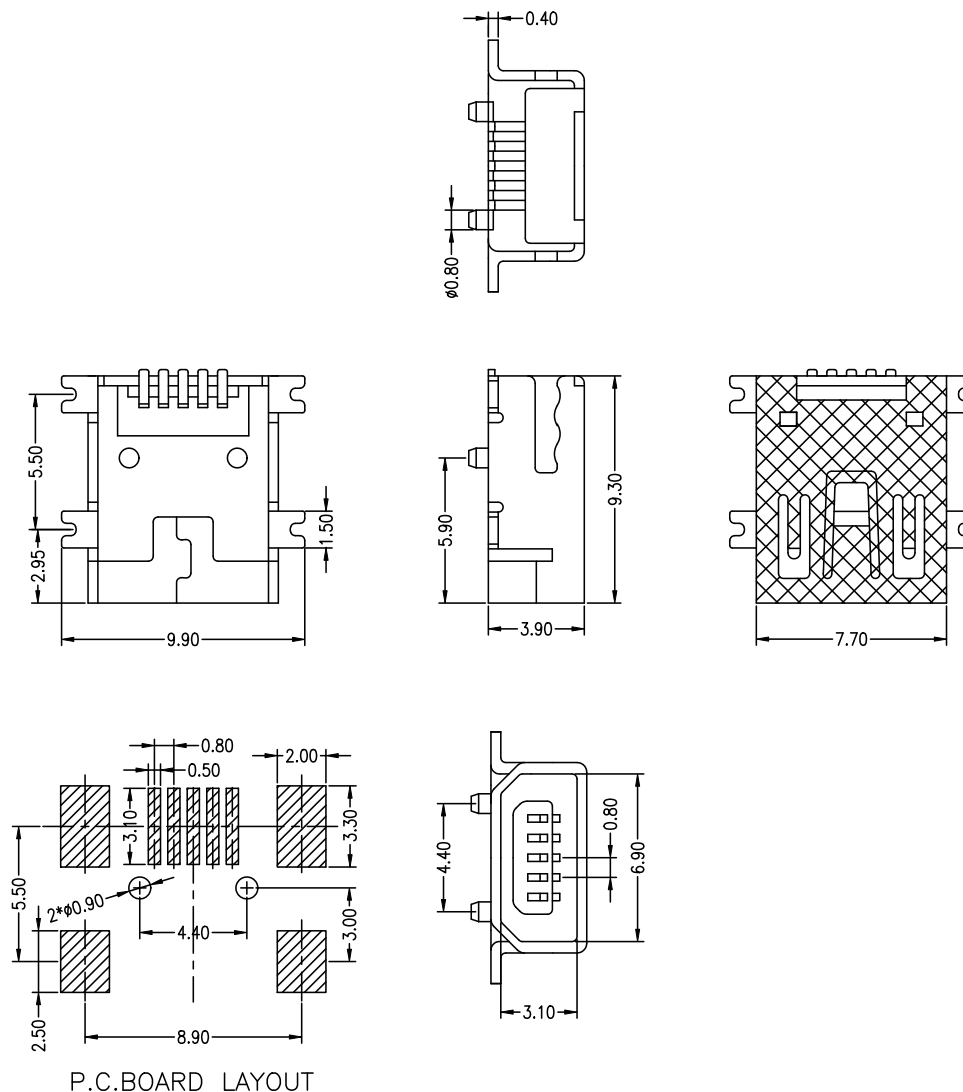

Art Nr:

RND 205-01057