

# Quick-Connect Terminal Block



## Features

- Anti-creeping
- Anti-flaming & high-temperature resistance material
- Safer & easier install and operate
- Certification: CE, TUV



## Mechanical Specification

Connection Capacity	IEC 0.5 ... 2.5 mm <sup>2</sup> (Solid Wire)
Stripping Length	10 ... 12 mm
Number of Positions	3
Operating Temperature	-45 ... 80 °C


 



## Electrical Specification

Voltage Rating	300 V
Current Rating	24 A
Contact Resistance	20 mOhm max.
Insulation Resistance	1 GOhm min. , 1 kV DC
Withstanding Voltage	2.5 kV AC, 1 min.

## Material Specification

Body Material	Polycarbonate
Spring Clip	SUS 301
Conductor Material	Copper, Tin Plated
Cover Material	PA66, UL94-V0

## Drawing

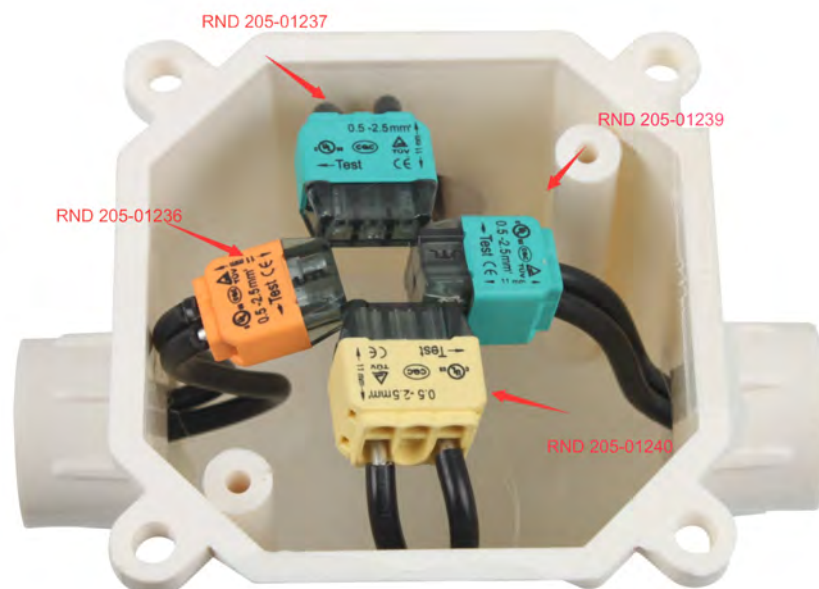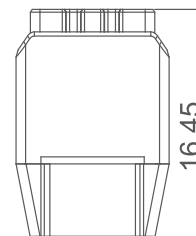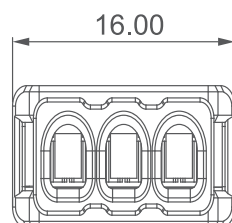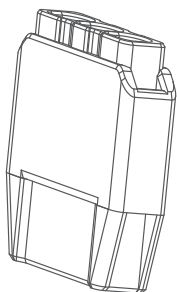

Art. Nr.  
RND 205-01237