

Null Modem Adapter


Specification

Current Rating	3 A
Dielectric Withstanding Voltage	500 VAC / 60 sec. RMS
Insulation Resistance @ 500 VDC	500 MOhm min.
Operating Temperature	-25 ... 105 °C
Connector Type A	D-Sub 9-Pin Plug
Connector Type B	D-Sub 9-Pin Socket
Adapter Type	Straight

Material Specification

Contacts	Brass
Insulator	PBT, UL94V-0
Shell	Cold Roller Steel
Screw	Brass Plated Nickel

Drawing & Pin Out

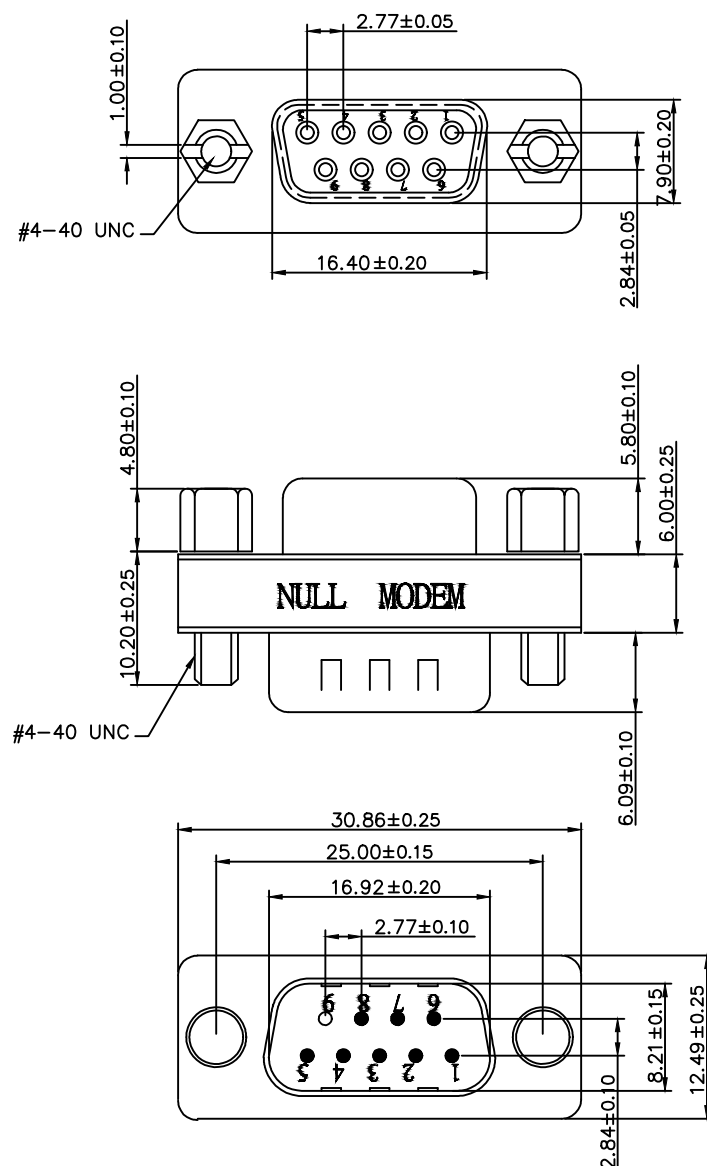

MA 005A 09F/M	GENDER	CHANGER
PIN OUT: 09Male		09Female
2	-----	3
3	-----	2
4	-----	1
	-----	6
5	-----	5
1	-----	4
6	-----	
7	-----	8
8	-----	7
G	-----	G

Art. Nr.
RND 205-01316