

TNC to TNC Adapter



Features


- Nickel-Plated brass body
- Commonly used in applications requiring 2 dissimilar RF interfaces to be connected
- RoHS compliant



Specification

Colour	Silver
Impedance	50 Ω
Adapter Type	Straight
Connector Type A	TNC Jack
Connector Type B	TNC Jack
Frequency Range	0 ... 4 GHz
Voltage Rating	500 V
Dielectric Withstanding Voltage	1.5 kV RMS

Drawing

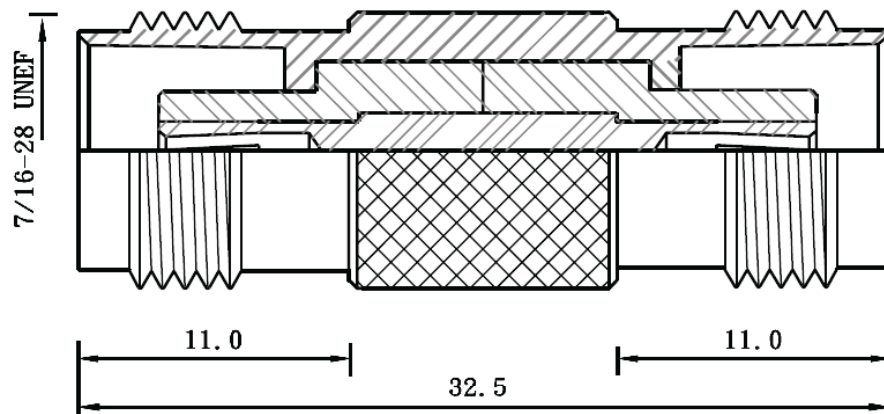

Material Specification

Body	Brass, Nickel Plated
Contact	PH / Bronze, Gold Plated
Insulator	POM

Art. Nr.
RND 205-01489