

BNC PLUG FOR RG179 CABLE



Features

- The BNC (Bayonet Neill-Concelman) plug is a widely used coaxial connector known for its quick and secure bayonet-style coupling mechanism
- RG179 is a lightweight and flexible coaxial cable that is known for its excellent signal integrity and low loss properties at higher frequencies
- This combination makes it suitable for applications where both signal quality and ease of use are essential




Specification

Impedance	75 Ohm
Frequency Range	0 ... 6 GHz
VSWR	1.5 max
Working Voltage	500V RMS @ Sea Level
Insulation Resistance	5 GOhm min.
Temperature Range	-40... 125 °C

Material Specification

Body	Brass, Nickel
Insulator	PTFE
Center Pin	Brass, Gold Plated

Drawing

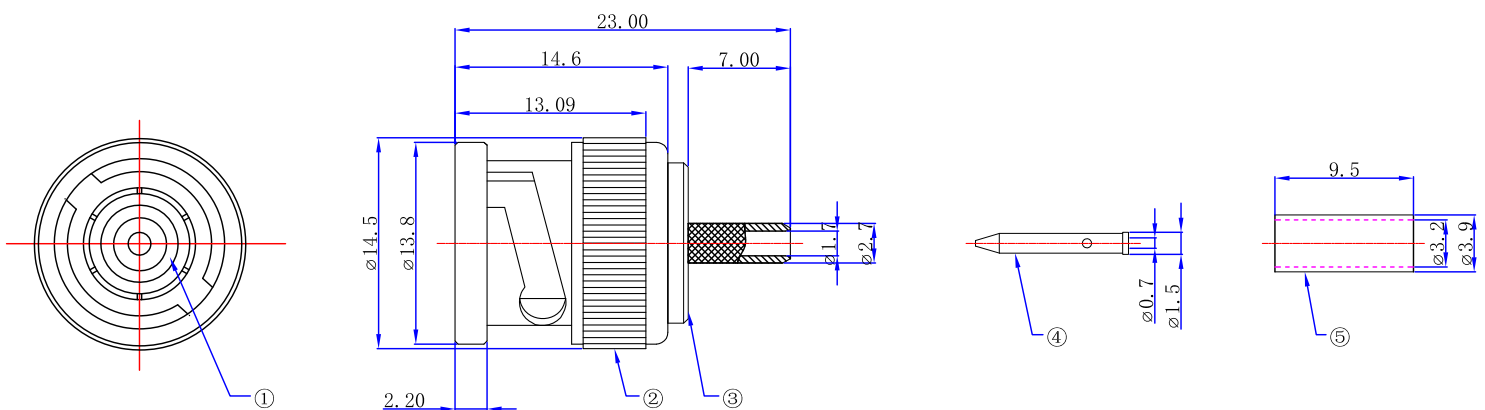

Art. Nr.
RND 205-01520