

BNC FEMALE HEAD WITH FLANGE PLATE



Features

- The BNC female head with a flange plate is designed for secure and stable mounting on surfaces such as panels, enclosures, or equipment cases
- The flange plate design offers a fixed installation point for interconnecting cables or equipment, maintaining signal integrity while preventing unintentional disconnections
- BNC female head with flange plate offers a robust and permanent mounting solution for BNC connectors, ensuring consistent signal quality and secure connections in various applications requiring reliable RF or video connectivity.




Specification

Impedance	50 Ohm
Frequency Range	0 ... 3 GHz
VSWR	1.45 max
Working Voltage	500V RMS @ Sea Level
Insulation Resistance	5 GOhm min.
Temperature Range	-35... 120 °C

Material Specification

Body	Brass, Nickel
Insulator	POM
Center Pin	Brass, Gold Plated

Drawing

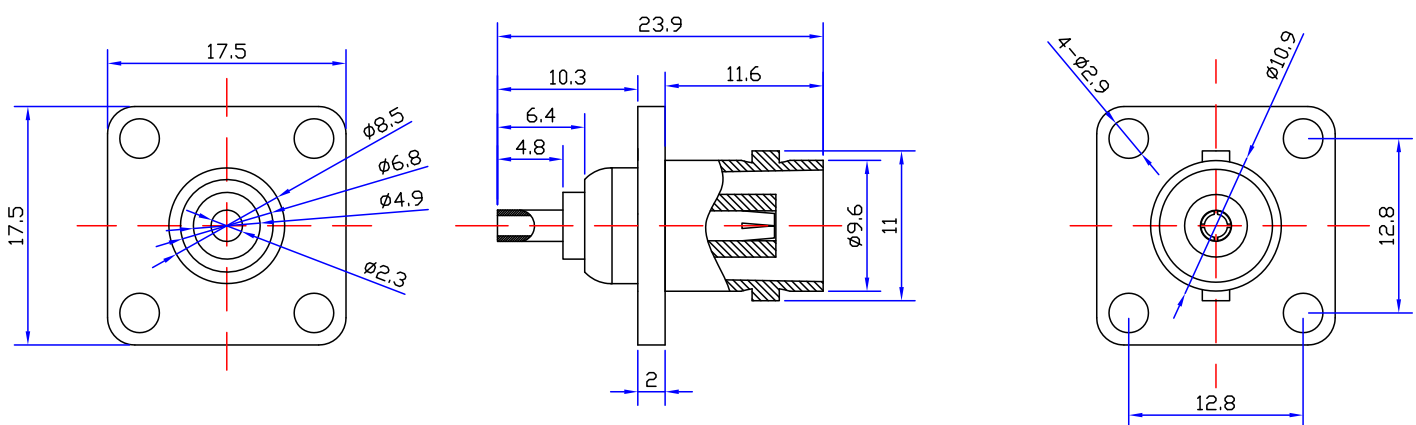

Art. Nr.
RND 205-01523