


Rotary DIP Switch

BCD 3+2

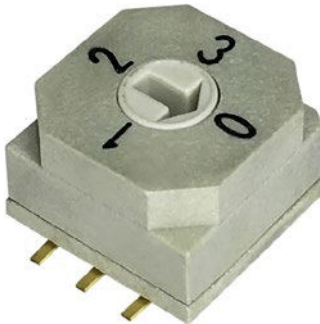

POSITION	Common C contacted ●		
	C	1	2
0	●		
1	●	●	
2	●		●
3	●	●	●

SPECIFICATION:

Switching type	BCD
Pins	3+2
Pitch	2.54 mm
Actuation	above
Switching capacity	0.5 A@ 24 VDC
Contact resistance	<100 mΩ
Contact material	Gold-plated
Test voltage	300 VAC
Temperature range	-10...+70 °C

Art. Nr.

RND 210-00115