

DIP switch


6P

FEATURES:

Electrical life 2,000 operations
 Switching rating 25mA, 24VDC
 Soldering temperature 260°C for 5±1sec

SPECIFICATION:

| | |
|--------------------|-----------------|
| Poles | 6 |
| Pitch | 2.54 mm |
| Actuation | above |
| Contact resistance | 50 mΩ |
| Contact material | Phosphor bronze |
| Test voltage | 500 VAC |
| Temperature range | -20...+70 °C |

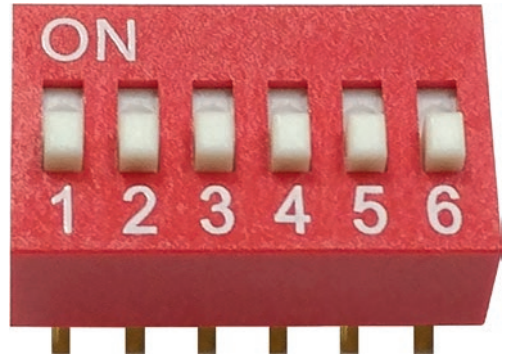

Art. Nr.

RND 210-00160

