

# DIP switch


4P

**FEATURES:**

- Electrical life 2,000 operations
- Switching rating 25mA, 24VDC
- Soldering temperature 260°C for 5±1sec
- With top tape seal

**SPECIFICATION:**

Poles	4
Pitch	2.54 mm
Actuation	above
Contact resistance	50 mΩ
Contact material	Phosphor bronze
Test voltage	500 VAC
Temperature range	-20...+70 °C

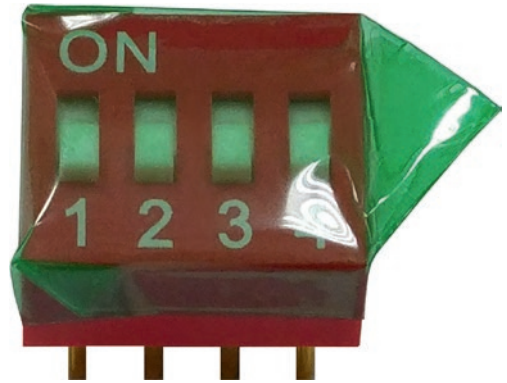

Art. Nr.

RND 210-00164

