

DIP switch


4P

FEATURES:

Electrical life	2,000 operation
Switching rating	25m , 24VDC
Soldering temperature	260°C for 5±1sec
With top tape seal	

SPECIFICATION:

Poles	4
Pitch	1.27 mm
Actuatio	above
Contact resistance	50 mΩ
Contact material	Phosphor bronze
Test voltage	500 VAC
Operating Temperature range	-30 ... 85 °C
Storage Temperature range	-30 ... 85 °C

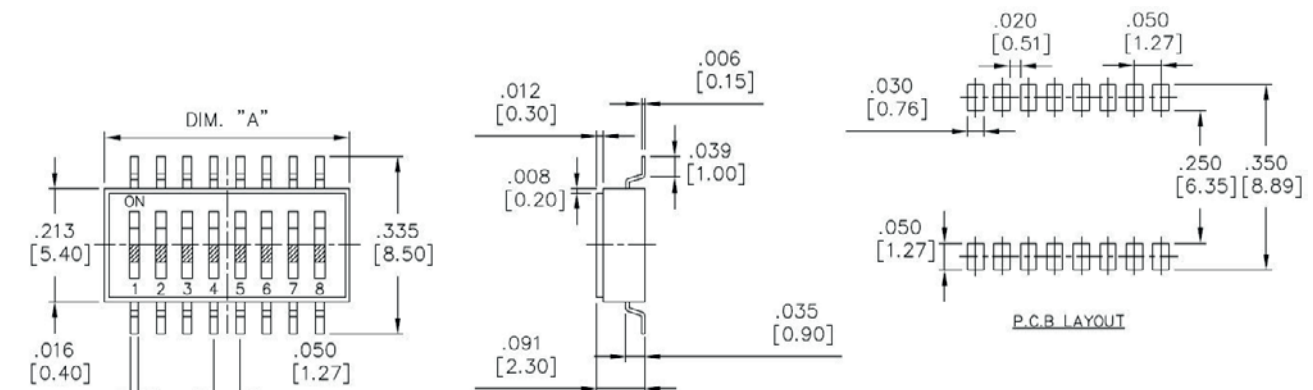

Art. Nr.

RND 210-00184