

DIP switch



8P

FEATURES:

- Electrical life 2,000 operations
- Switching rating 25mA, 24VDC
- Soldering temperature 260°C for 5±1sec
- With top tape seal

SPECIFICATION:

Poles	8
Pitch	1.27 mm
Actuation	above
Contact resistance	50 mΩ
Contact material	Phosphor bronze
Test voltage	500 VAC
Operating Temperature range	-30 ... 85 °C
Storage Temperature range	-30 ... 85 °C

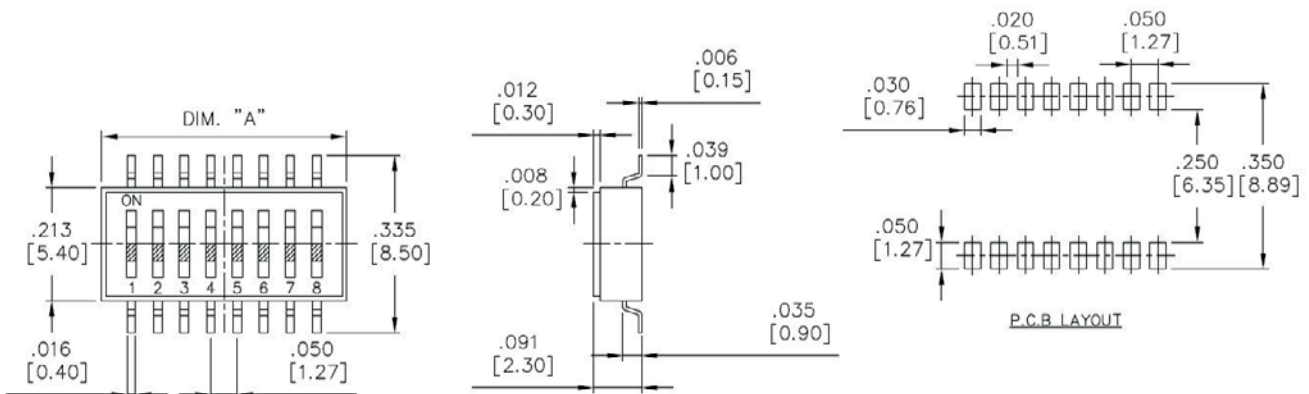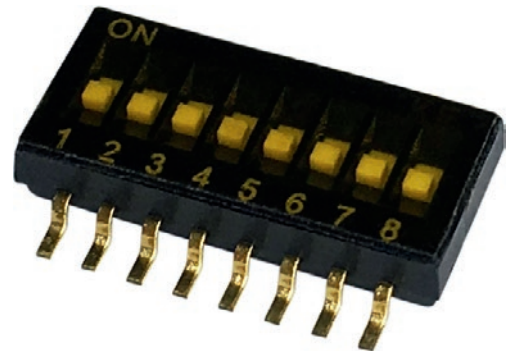

Art. Nr.

RND 210-00186